


19" Front Panel With SUB-D Cut-Out

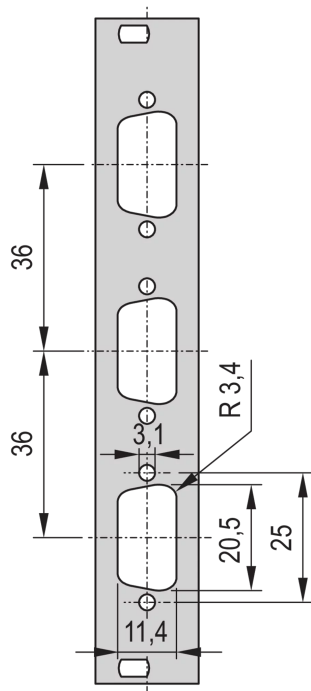

19" Front Panel with SUB-D Cut-Out or FDDI Cut-Out.

CERTIFICATIONS



CARACTERÍSTICAS

19" Front Panel with Cutout for Sub-D, ST type 3 or FDDI

ESPECIFICAÇÕES


Profundidade (D):	2.5mm
Material:	Aluminio
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Número de catálogo	Rack Height	Rack Width	Quantidade por embalagem	Front Finish	Rear Finish	Number of Pins
30118-332	3U	4HP	1	Painted	Conductive	(3) 9
30118-334	3U	4HP	1	Painted	Conductive	(1) 25
30118-336	3U	4HP	1	Painted	Conductive	(2) 9
30118-338	3U	4HP	1	Painted	Conductive	(1) 9
30118-335	3U	4HP	1	Painted	Conductive	(2) 25

Table 2/2

Número de catálogo	Código de cor	Acabamento	Altura (H)	Largura (W)	Envio rápido
30118-332	RAL 7035	Pintura electrostática com Acabamento Texturado	128.4mm	19.98mm	Não
30118-334	RAL 7035	Pintura electrostática com Acabamento Texturado	128.4mm	19.98mm	Não
30118-336	RAL 7035	Pintura electrostática com Acabamento Texturado	128.4mm	19.98mm	Não
30118-338	RAL 7035	Pintura electrostática com Acabamento Texturado	128.4mm	19.98mm	Não
30118-335	RAL 7035	Pintura electrostática com Acabamento Texturado	128.4mm	19.98mm	Não

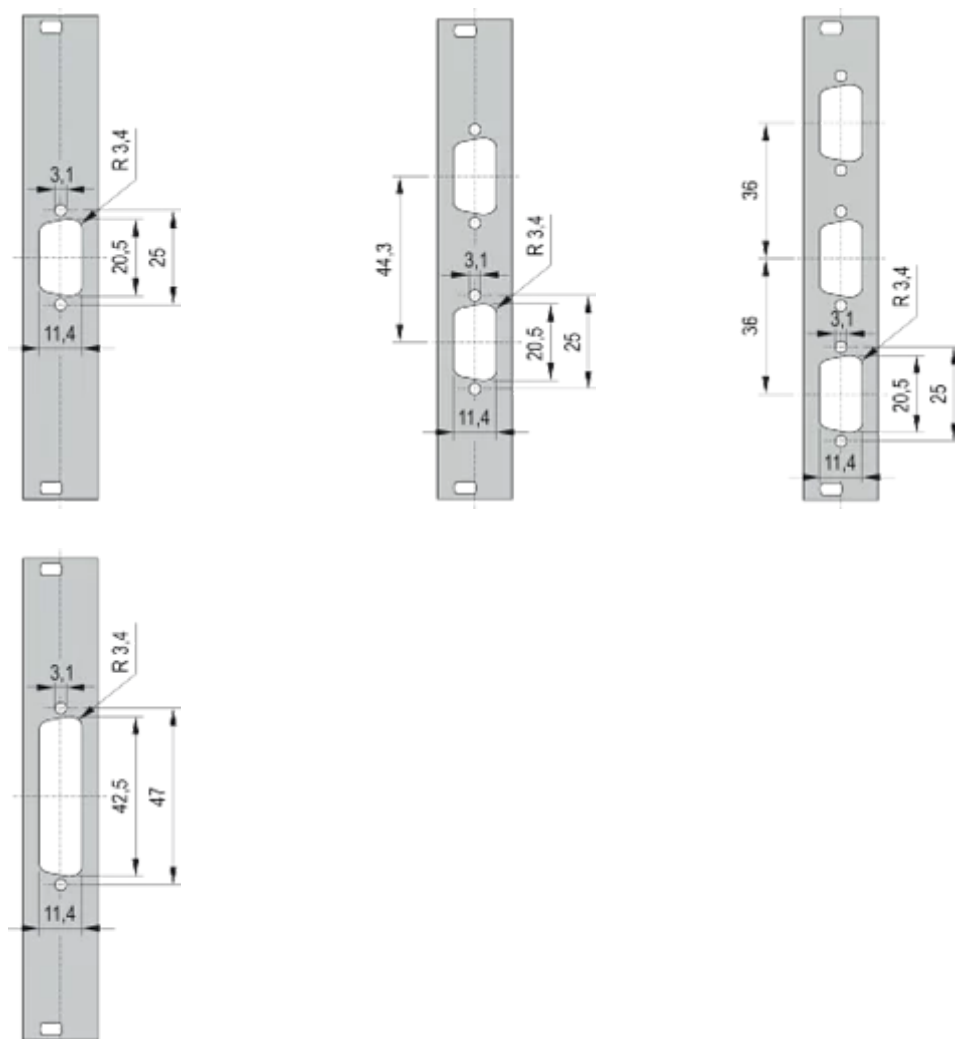

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE