


On Board Rack

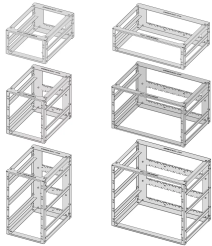

Suitable for ongoing vibrations, shock, high temperatures, and high humidity.

CERTIFICATIONS



CARACTERÍSTICAS

For mobile railway applications

Suitable for ongoing vibrations, shock, high temperatures, and high humidity

Suitable for 1, 2, or 3 U SNCF subracks (NF F61-005, CF 60-002)

Rear side is equipped for standard connectors; crossbar can be custom-coded for the SNCF coding pins

Crossbar with integrated cable channel

Several racks can be stacked or fitted in rows

Produced using a welding process, certified to EN 15085 (CL2)

Stainless Steel welds passivated to prevent corrosion

ESPECIFICAÇÕES

Static Load:	25kg
Profundidade:	341.8mm
Product Type:	Rack
Em conformidade com:	SNCF NFF 61005; SNCF NFF 60002
Frame Material:	Aço

Table 1/2

Número de catálogo	Rack Height	Altura	Rack Width	Largura	Quantidade por embalagem	Material
10170-017	9U	423.4mm	36HP	252.65mm	1	Aço inoxidável
10170-016	9U	423.4mm	84HP	496.4mm	1	Aço inoxidável
10170-015	3U	156.7mm	36HP	252.65mm	1	Aço inoxidável
10170-012	6U	290mm	84HP	496.4mm	1	Aço inoxidável
10170-014	3U	156.7mm	84HP	496.4mm	1	Aço inoxidável
10170-013	6U	290mm	36HP	252.65mm	1	Aço inoxidável

Table 2/2

Número de catálogo	Envio rápido
10170-017	Não
10170-016	Não
10170-015	Não
10170-012	Não
10170-014	Não
10170-013	Não

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE