
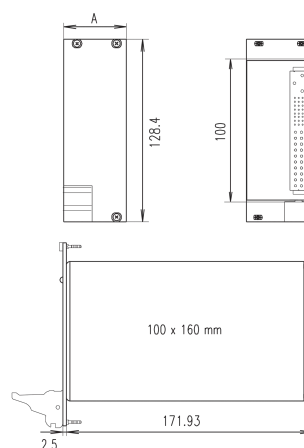


PSU 19" for CompactPCI, DC/DC, 3 U, 8 HP

NÚMERO DE CATÁLOGO

13100-142

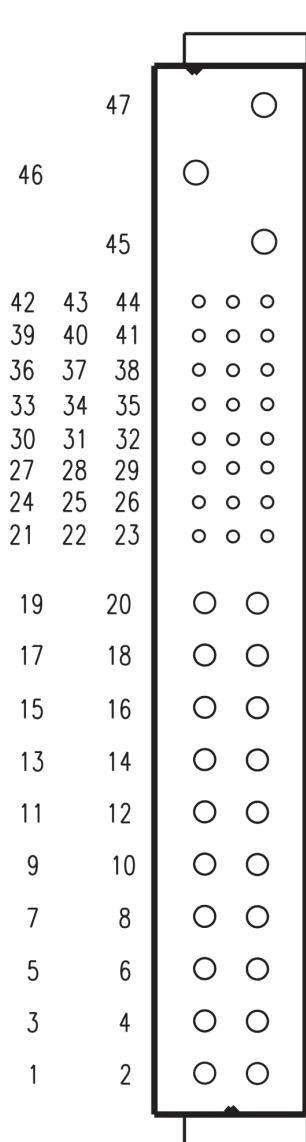

Pluggable 19" Power Supply with P47 connector, for CompactPCI applications.

CERTIFICATIONS



CARACTERÍSTICAS

Connector P47 and CompactPCI signalling

4 output voltages

Redundant operation with Current Share Bus (CSB), hot-swap

CARATERÍSTICAS DO PRODUTO

Product Type: Power Supply

Tipo: 19" DC/DC Converter

Works With: CompactPCI and VME64x

Tensão de entrada DC: 36 – 75V

Power: 250W

Number of Output Voltages: 4

Voltage 1: 5V

Current 1: 40A

Voltage 2: 3.3V

Current 2: 40A

Voltage 3: 12V

Current 3: 5.5A

Voltage 4: -12V

Current 4: 2A

Rack Height: 3U

Rack Width: 8HP

Profundidade: 171.93mm

Net Weight: 0.94kg

Quantidade por embalagem: 1

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE