


VMEbus System, 7 U, 12 Slot, for Transition Modules, Open Frame PSU

NÚMERO DE CATÁLOGO

20836-716

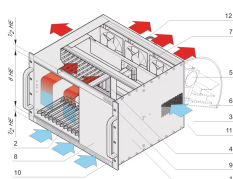

VME system for 12 VME boards 6 U, 160 mm. The power for the system is supplied by an open frame power supply. A fan control module monitors the fans, the temperature and voltage.

CERTIFICATIONS



CARACTERÍSTICAS

System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; Backplane conforms to VITA 1.1-1994

PSU, open frame, 444 W (400 W at < 180 VAC)

Backplane VME 12 slot, 6 U, J1/J2 monolithic in accordance with VITA 1-1994

Heat dissipation by 3 fans (rear panel), cooling from front to rear; temperature-controlled with fan control module (FCM)

Display module for DC operating voltages, fan and temperature alarm

System for vertical board mounting with board formats, Front: 6 U, 160 mm deep, Rear: 6 U, 12 HP, 80 mm deep; for transition modules

CARATERÍSTICAS DO PRODUTO

Product Type: System

Number of Slots: 12

Tipo: 19" Rack Mount

Backplane Type: 6 U VME64

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Tensão de entrada AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 7U

Power Supply Type: Open Frame

Power Supply Included: Sim

Rear I/O: Sim

Em conformidade com: ANSI/VITA 1.1-1994

Profundidade: 355mm

Altura: 310.35mm

Largura: 449mm

Power: 450W

Net Weight: 15kg

Quantidade por embalagem: 1

DETALHES ADICIONAIS DO PRODUTO

Modified systems available on request.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE