


CPCI System With Pluggable PSU, PSB H.110, 4 U, 8 Slot

NÚMERO DE CATÁLOGO

24579-135

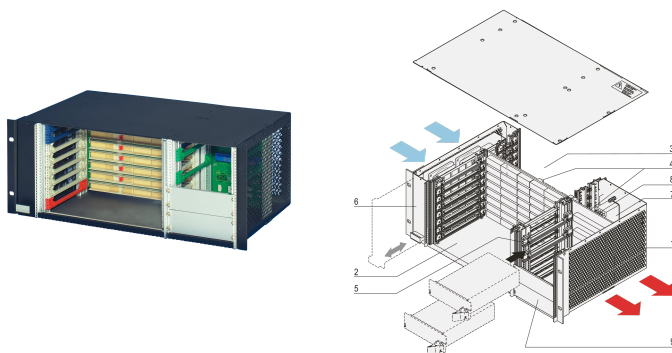

4 U CompactPCI System with PSB and H.110, with horizontal Card Cage for eight 6 U Boards, eighth RTM Boards and two CompactPCI 3 U Pluggable Power Supplies. Option to build in up to four pluggable Power Supplies.

CERTIFICATIONS



CARACTERÍSTICAS

System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11); Backplane, conforms to PICMG 2.16

System with horizontal card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Monolithic backplane for (signals and power) 64-bit CompactPCI; PSB (Package Switched Backplane), PICMG 2.16; H.110, 8 slot, 6 U, 64 bit CompactPCI (2 fabric/switch slots, 6 node slots H.110), system slot left; Integrated power backplane with 2 x P 47 connectors

Heat dissipation by hot-swap fan unit, airflow left to right

Prepared to accept two 19" CompactPCI PSUs 250 W (3 U, 8 HP)

CARATERÍSTICAS DO PRODUTO

Product Type: System

Number of Slots: 8

Tipo: 19" Rack Mount

Backplane Type: 6 U CompactPCI with PSB and H.110

Data Transfer: 64-bit PCI Bus; GbE

Power per Slot: 40W

Tensão de entrada AC: 100 – 240V

Airflow Direction: Left to Right

Rack Height: 4U

Power Supply Type: (2) Pluggable PSU

Power Supply Included: Não

Rear I/O: Sim

Em conformidade com: PICMG 2.0 R3.0

Profundidade: 275mm

Altura: 177mm

Quantidade por embalagem: 1

DETALHES ADICIONAIS DO PRODUTO

Modified systems available on request.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE