 



Socket Strip, IEC C13, Metered

NÚMERO DE CATÁLOGO

60110-296

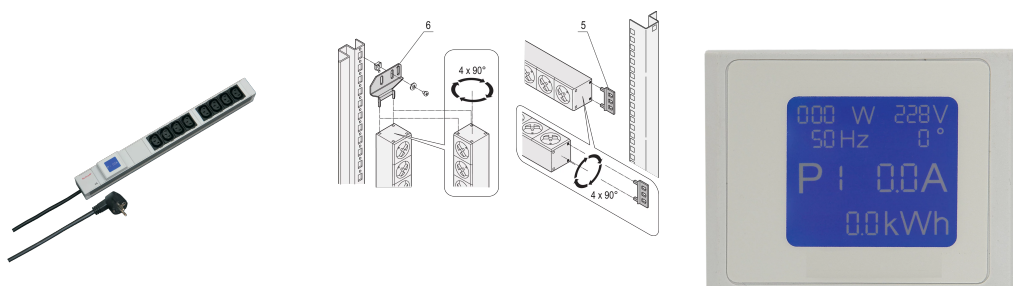

PDU with local power meter. Relevant Power data are shown on an integrated display.

CERTIFICATIONS



CARACTERÍSTICAS

Socket strips can be rotated through all four directions (in 90° increments) during installation

Mounting height 1 U

Integrated measurement and display via local display unit

Socket strips with IEC 60320-C13 sockets

Horizontal and vertical mounting

CARATERÍSTICAS DO PRODUTO

Product Type: Socket Strip

Tipo de soquete: IEC C13

Socket Quantity: 8

Cor: Grey

Switched Outlets: Sim

Length: 438.5mm

Tensão AC: 230V

Profundidade: 44mm

Material: Alumínio; Polyamide

Quantidade por embalagem: 1

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portfólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE