


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, SNCF

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

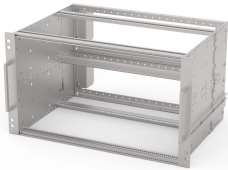

CERTIFICATIONS



CARACTERÍSTICAS

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

ESPECIFICAÇÕES

Static Load:	15kg
Material:	Aluminio
Acabamento:	Anodized; Passivated

Em conformidade com: IEC 60297-3-103; SNCF NFF 61005; SNCF NFF 60002

EMC Shielding: Não

Product Type: Subrack/Chassis

Table 1/2

Número de catálogo	Rack Height	Rack Width	Profundidade	Quantidade por embalagem	For Mounting	Board Depth
21500-027	6U	84HP	320mm	1	Backplane	220mm
21500-029	3U	84HP	320mm	1	Backplane	220mm
21500-070	6U	36HP	320mm	1	Backplane	220mm
21500-067	3U	36HP	320mm	1	Backplane	220mm

Table 2/2

Número de catálogo	EMC Gasket Type	Shock and Vibration Tolerance	Inclui alça	Instalação	Certifications	Envio rápido
21500-027	Textile	5g (force)	Sim	Rack	RoHS, SNCF	Não
21500-029	Textile	5g (force)	Sim	Rack	RoHS, SNCF	Não
21500-070	Textile	5g (force)	Sim	Rack	RoHS	Não
21500-067	Textile	5g (force)	Sim	Rack	RoHS	Não

DETALHES ADICIONAIS DO PRODUTO

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for sub racks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for sub racks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos

representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE