


# EuropacPRO Mounting Plate for Use With Cover Plate

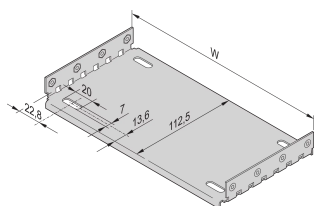

Mounting plate for use with cover plates for installation and fixing of heavy components. Full width mounting plates (as wide as the subrack or the system case) are fixed to the side panels. The partial width mounting plates are fixed to the side panel and horizontal rail by means of an assembly strip.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

## CERTIFICATIONS



## CARACTERÍSTICAS

For installation and fixing of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

A guide rail can be fitted in first and last slot position

In addition to the mounting plate EMC cover plates can also be fitted to the subrack

Guide rails type 4.4 and "strengthened" cannot be used

## ESPECIFICAÇÕES

|                             |                |
|-----------------------------|----------------|
| <b>Material:</b>            | Aluminio       |
| <b>Família de produtos:</b> | EuropacPRO     |
| <b>Product Type:</b>        | Mounting Plate |
| <b>Works With:</b>          | Subracks       |

Table 1/1

| Número de catálogo | Rack Width | Quantidade por embalagem | Profundidade | Largura | Certifications | Envio rápido |
|--------------------|------------|--------------------------|--------------|---------|----------------|--------------|
|--------------------|------------|--------------------------|--------------|---------|----------------|--------------|

|           |      |   |         |          |      |     |
|-----------|------|---|---------|----------|------|-----|
| 34563-004 | 84HP | 1 | 112.5mm | 431.35mm | RoHS | Não |
| 34563-019 | 63HP | 1 | 172.5mm | 324.67mm | RoHS | Não |
| 34563-014 | 42HP | 1 | 172.5mm | 217.99mm | RoHS | Não |
| 34563-009 | 28HP | 1 | 172.5mm | 146.88mm | RoHS | Não |
| 34563-003 | 63HP | 1 | 112.5mm | 324.67mm | RoHS | Não |
| 34563-002 | 42HP | 1 | 112.5mm | 217.99mm | RoHS | Não |
| 34563-001 | 28HP | 1 | 112.5mm | 146.88mm | RoHS | Não |
| 34563-024 | 84HP | 1 | 172.5mm | 431.35mm | RoHS | Não |
| 34563-044 | 84HP | 1 | 412.5mm | 431.35mm |      | Não |
| 34563-042 | 84HP | 1 | 352.5mm | 431.35mm |      | Não |
| 34563-028 | 84HP | 1 | 292.5mm | 431.35mm |      | Não |
| 34563-026 | 84HP | 1 | 232.5mm | 431.35mm |      | Não |

## AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



O nosso forte portefólio de marcas:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**