

Front Panel, Flat, Unshielded, D-Sub Cutouts



Flat front panel with cutout for D-Sub connectors.
Unshielded version.

CERTIFICATIONS



CARACTERÍSTICAS

Non-shielded version

Al, 2.5 mm, front anodized, rear conductive

ESPECIFICAÇÕES

Rack Height:	3U
Rack Width:	4HP
Material:	Aluminio
Acabamento:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Tipo:	Front Panel without Handle

Table 1/2

Número de catálogo	Quantidade por embalagem	Instalação	Front Finish	Rear Finish	Number of Pins	Treated Edges
30118-341	1	Screw-on Front	Anodized	Conductive	(3) 9	Não
30118-342	1	Screw-on Front	Anodized	Conductive	(1) 15	Não
30118-343	1	Screw-on Front	Anodized	Conductive	(1) 25	Não
30118-344	1	Screw-on Front	Anodized	Conductive	(2) 9	Não
30118-345	1	Screw-on Front	Anodized	Conductive	(2) 15	Não
30118-346	1	Screw-on Front	Anodized	Conductive	(2) 25	Não
30118-347	1	Screw-on Front	Anodized	Conductive	(3) 9	Não

Table 2/2

Número de catálogo	Em conformidade com	Profundidade (D)	EMC Shielding	Altura (H)	Largura (W)	Envio rápido
30118-341	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Não	128.4mm	19.98mm	Não
30118-342	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Não	128.4mm	19.98mm	Não
30118-343	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Não	128.4mm	19.98mm	Não
30118-344	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Não	128.4mm	19.98mm	Não
30118-345	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Não	128.4mm	19.98mm	Não
30118-346	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Não	128.4mm	19.98mm	Não
30118-347	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Não	128.4mm	19.98mm	Não


DETALHES ADICIONAIS DO PRODUTO


Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMAS

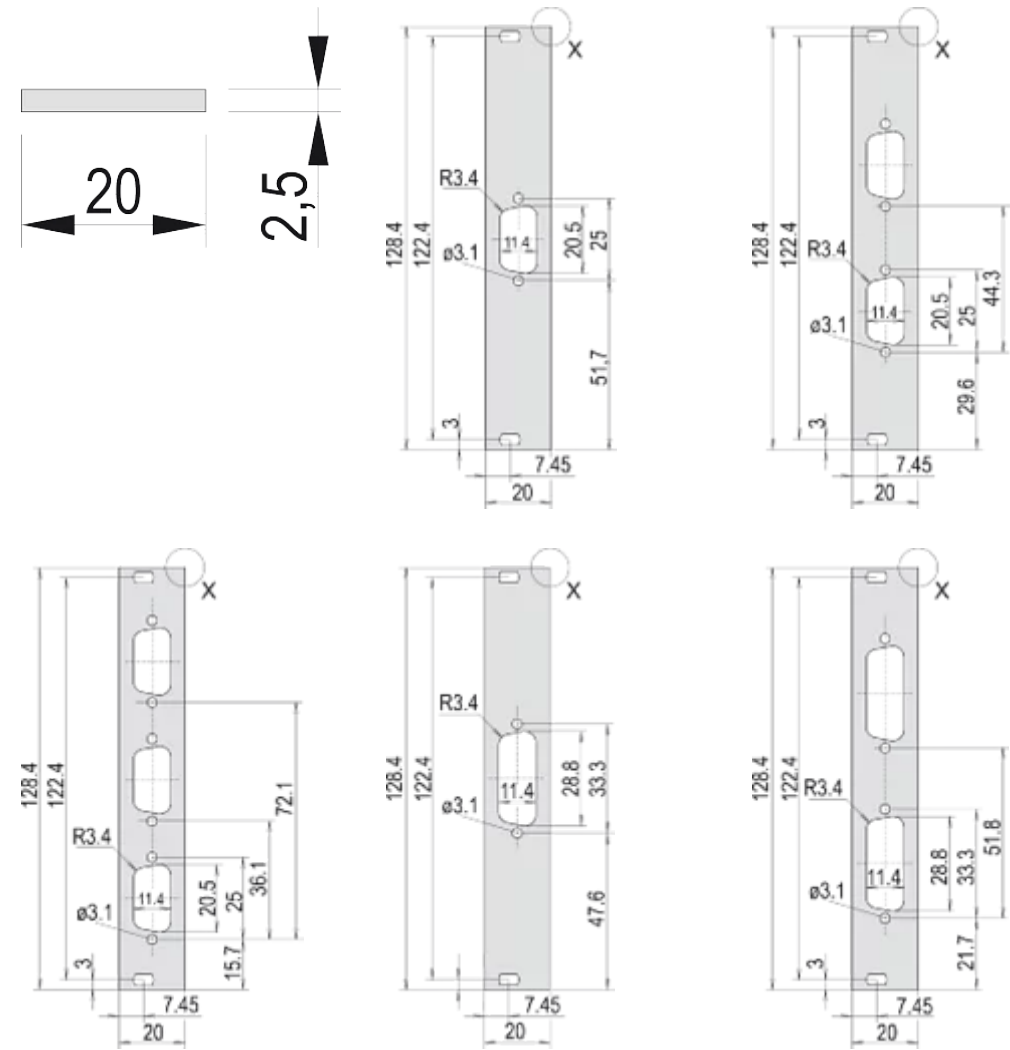

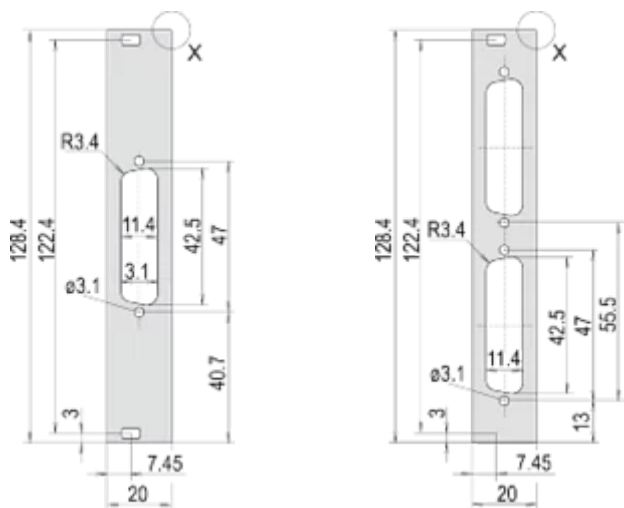

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE