


# MultipacPRO 19" Chassis, Steel, AlZn, Plain Top and Base

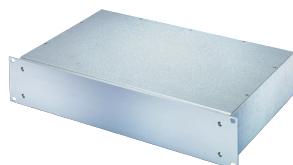

This 19" chassis is a form of subrack which accepts horizontal board mounting or the mounting of non-standard components like transformers or other heavy load accessories typically mounted on a chassis plate. This version is produced from sheet metal, Al-Zn coated and have plain top and bottom covers.

## CERTIFICATIONS



## CARACTERÍSTICAS

Steel (AlZn coated) with Al extrusion front panel

Detachable front and rear panel for easy machining

IP 20, in accordance with IEC 60529

Supplied as space-saving flat-pack

EMC shielding: Approx. 20dB(A) at 2GHz without shielding material. >40dB(A) at 1Ghz with addition of stainless steel gasket between front panel and case body

Internal and external dimensions in accordance with: IEC 60297-3-101

EMC shielding: Approx. 20dB(A) at 2 GHz without shielding material. >40dB(A) at 1 GHz with addition of stainless steel gasket between front panel and case body

## ESPECIFICAÇÕES

|                             |                      |
|-----------------------------|----------------------|
| <b>Acabamento:</b>          | Aluminum-Zinc Plated |
| <b>Família de produtos:</b> | MultipacPRO          |
| <b>EMC Shielding:</b>       | No (Retrofittable)   |
| <b>Tipo:</b>                | Solid                |

**Material:** Aço  
**Product Type:** Subrack/Chassis

Table 1/1

| Número de catálogo | Rack Height | Profundidade | Usable Width | Instalação | Em conformidade com              | Envio rápido |
|--------------------|-------------|--------------|--------------|------------|----------------------------------|--------------|
| 20860-120          | 1U          | 220mm        | 447mm        | Rack       | IEC 60297-3-100, IEC 60297-3-105 | Não          |
| 20860-122          | 1U          | 340mm        | 447mm        | Rack       | IEC 60297-3-100, IEC 60297-3-105 | Não          |
| 20860-121          | 1U          | 280mm        | 447mm        | Rack       | IEC 60297-3-100, IEC 60297-3-105 | Não          |
| 20860-127          | 2U          | 340mm        | 447mm        | Rack       | IEC 60297-3-100                  | Não          |
| 20860-126          | 2U          | 280mm        | 447mm        | Rack       | IEC 60297-3-100                  | Não          |

## DETALHES ADICIONAIS DO PRODUTO

Please order front handles separately.

Telescopic slides cannot be used.

Further versions with steel front panel (pizza box) available on request.

Standardised internal mounting kits cannot be used.

## AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



O nosso forte portfólio de marcas:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**