

Plug-In Unit Front Panel for Static Trapezoid Handle



The front panel enables the assembly of a plastic or Alu-profile static trapezoid handle. The front panel cannot be shielded with a textile gasket.

CERTIFICATIONS



CARACTERÍSTICAS

Front panel, unshielded

Front panel, Al, 2.5 mm, front anodized, conductive

ESPECIFICAÇÕES

Profundidade (D):	2.5mm
Material:	Aluminio
Acabamento:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Tipo:	Front Panel for Handle (PIU)

Table 1/3

Número de catálogo	Rack Height	Rack Width	Quantidade por embalagem	Tipo de alça	Instalação	Front Finish
--------------------	-------------	------------	--------------------------	--------------	------------	--------------


30847-602	3U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-603	3U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-604	3U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-605	3U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-625	6U	3HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-606	3U	7HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-607	3U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-626	6U	4HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-608	3U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-627	6U	5HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-609	3U	12HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-628	6U	6HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized

30847-630	6U	8HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized
30847-631	6U	10HP	1	Trapezoid, Static, Aluminum Profile	Screw-on Front	Anodized

Table 2/3						
Número de catálogo	Rear Finish	Treated Edges	Em conformidade com	EMC Shielding	Altura (H)	Largura (W)
30847-602	Conductive	Não	IEC 60297-3-101	Não	128.4mm	14.9mm
30847-603	Conductive	Não	IEC 60297-3-101	Não	128.4mm	20mm
30847-604	Conductive	Não	IEC 60297-3-101	Não	128.4mm	25mm
30847-605	Conductive	Não	IEC 60297-3-101	Não	128.4mm	30.1mm
30847-625	Conductive	Não	IEC 60297-3-101	Não	261.8mm	14.9mm
30847-606	Conductive	Não	IEC 60297-3-101	Não	128.4mm	35.2mm
30847-607	Conductive	Não	IEC 60297-3-101	Não	128.4mm	40.3mm
30847-626	Conductive	Não	IEC 60297-3-101	Não	261.8mm	20mm
30847-608	Conductive	Não	IEC 60297-3-101	Não	128.4mm	50.5mm
30847-627	Conductive	Não	IEC 60297-3-101	Não	261.8mm	25mm
30847-609	Conductive	Não	IEC 60297-3-101	Não	128.4mm	60.6mm
30847-628	Conductive	Não	IEC 60297-3-101	Não	261.8mm	30.1mm
30847-630	Conductive	Não	IEC 60297-3-101	Não	261.8mm	40.3mm
30847-631	Conductive	Não	IEC 60297-3-101	Não	261.8mm	50.5mm

Table 3/3

Número de catálogo	Envio rápido
30847-602	Não
30847-603	Não
30847-604	Não
30847-605	Não
30847-625	Não
30847-606	Não
30847-607	Não
30847-626	Não
30847-608	Não
30847-627	Não
30847-609	Não
30847-628	Não
30847-630	Não
30847-631	Não

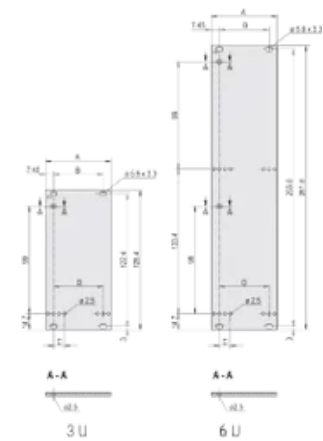

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE