


Plug-In Unit U-Profile Front Panel for XL Handle

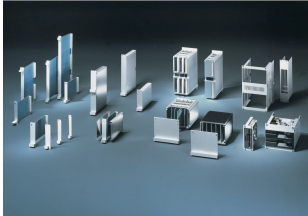

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.

CERTIFICATIONS



CARACTERÍSTICAS

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

ESPECIFICAÇÕES

Material:	Aluminio
Acabamento:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Tipo:	Front Panel for Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Número de catálogo	Rack Width	Quantidade por embalagem	Tipo de alça	Instalação	Gasket Type	Front Finish
30849-153	4HP	1	XL	Screw-on Front	Textile EMC	Anodized

Número de catálogo	Rack Width	Quantidade por embalagem	Tipo de alça	Instalação	Gasket Type	Front Finish
30849-154	4HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-156	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-155	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-158	12HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-157	12HP	1	XL	Screw-on Front	Textile EMC	Anodized

Table 2/3

Número de catálogo	Rear Finish	Treated Edges	Em conformidade com	Profundidade (D)	Altura (H)	Rack Height
30849-153	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-154	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-156	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-155	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-158	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-157	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U

Table 3/3

Número de catálogo	Largura (W)	Envio rápido
30849-153	20mm	Não
30849-154	20mm	Não


Número de catálogo	Largura (W)	Envio rápido
30849-156	40.3mm	Não
30849-155	40.3mm	Não
30849-158	60.6mm	Não
30849-157	60.6mm	Não

DETALHES ADICIONAIS DO PRODUTO

Delivery is exclusively in standard pack quantity, Please order EMC textile gasket and microswitch separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMAS

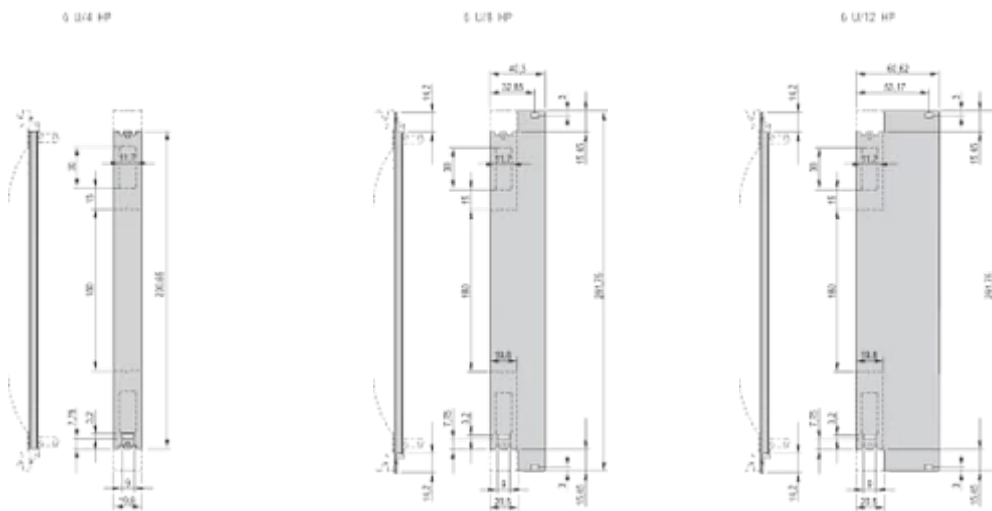

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE