


PSU 19" AC/DC Maxpower 50 W, Single

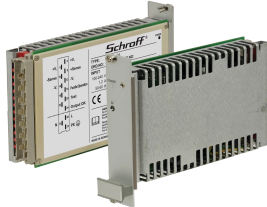

Redundancy with active OR decoupling; No base load required; Automatic load distribution depending on PSU temperature; No current share line required between power supplies; Quasi-resonant topology reduces EMC emissions.

CERTIFICATIONS



CARACTERISTICAS

Wide input voltage range 90 ... 253 VAC and 100 ... 360 VDC

1 output voltage

Signalling: Output voltage OK

Including front panel

Standby (no load) Power <1.5 W

Efficiency up to 88%

ESPECIFICAÇÕES

Table 1/2

Número de catálogo	Tipo	Tensão de entrada AC	Power	Number of Output Voltages	Voltage 1	Current 1
13100-174	19" Switched-Mode	90 – 264V	53W	1	48V	1.1A
13100-172	19" Switched-Mode	90 – 264V	50W	1	15V	3.4A

Número de catálogo	Tipo	Tensão de entrada AC	Power	Number of Output Voltages	Voltage 1	Current 1
13100-173	19" Switched-Mode	90 – 264V	50W	1	24V	2.1A
13100-170	19" Switched-Mode	90 – 253V	50W	1	5V	10A
13100-171	19" Switched-Mode	90 – 264V	50W	1	12V	4.2A

Table 2/2

Número de catálogo	Rack Height	Rack Width	Quantidade por embalagem	Envio rápido
13100-174	3U	6HP	1	Não
13100-172	3U	6HP	1	Não
13100-173	3U	6HP	1	Não
13100-170	3U	6HP	1	Não
13100-171	3U	6HP	1	Não

DETALHES ADICIONAIS DO PRODUTO

Output data at Ta= -25 ... 50 °C.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE