


U-profile Front Panel, Shieldable, D-Sub Cutouts

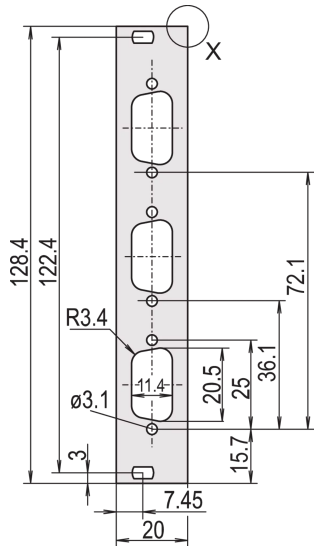

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFICATIONS



CARACTERÍSTICAS

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

ESPECIFICAÇÕES

Profundidade (D):	2.5mm
Rack Height:	3U
Rack Width:	4HP
Material:	Aluminio
Acabamento:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Tipo:	Front Panel without Handle

EMC Shielding: No (Retrofittable)

Table 1/2

Número de catálogo	Quantidade por embalagem	Instalação	EMC Gasket Type	Front Finish	Rear Finish	Number of Pins
30849-751	1	Screw-on Front	Textile	Anodized	Conductive	(3) 9
30849-750	1	Screw-on Front	Textile	Anodized	Conductive	(2) 9
30849-752	1	Screw-on Front	Textile	Anodized	Conductive	(1) 15
30849-754	1	Screw-on Front	Textile	Anodized	Conductive	(1) 25
30849-753	1	Screw-on Front	Textile	Anodized	Conductive	(2) 15
30849-755	1	Screw-on Front	Textile	Anodized	Conductive	(2) 25
30849-749	1	Screw-on Front	Textile	Anodized	Conductive	(1) 9

Table 2/2

Número de catálogo	Treated Edges	Em conformidade com	Altura (H)	Largura (W)	Envio rápido
30849-751	Não	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Não
30849-750	Não	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Não
30849-752	Não	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Não
30849-754	Não	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Não
30849-753	Não	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Não
30849-755	Não	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Não
30849-749	Não	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Não

DETALHES ADICIONAIS DO PRODUTO


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMAS

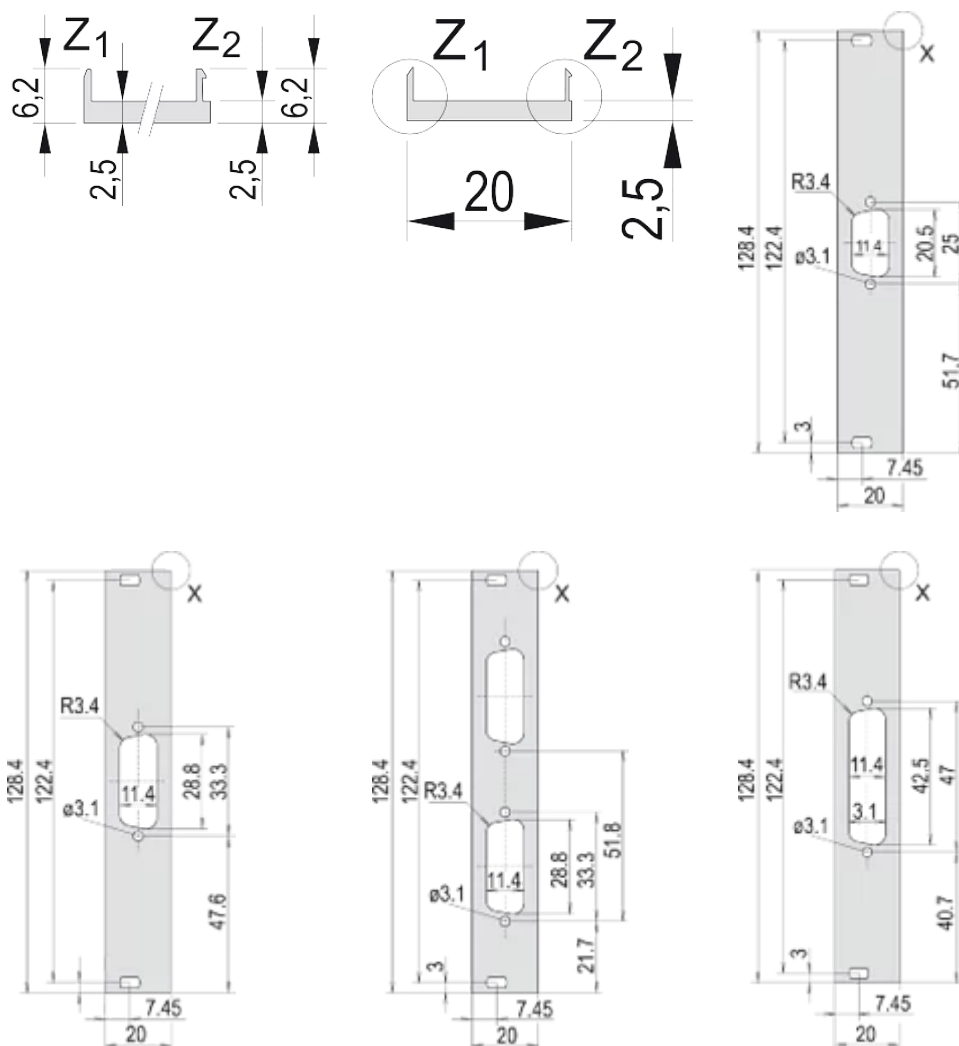

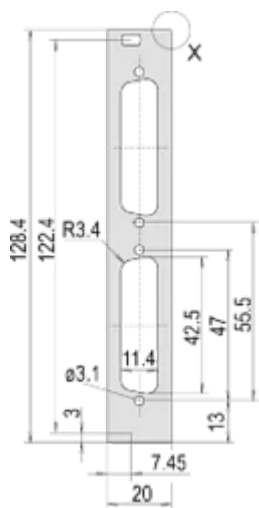

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE