


# Z-Rail for Connector, EN 60603-2, DIN 41612

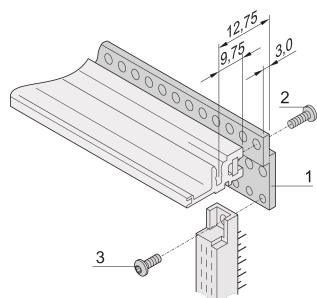

Z-rail for connector in accordance with EN 60603-2 (DIN 41612).

## CERTIFICATIONS



## CARACTERÍSTICAS

Aluminum extrusion, anodized

Z-rails are bolted to the subrack for connector mounting (rear horizontal rail type ST, threaded insert inserted, insulation strip)

For connectors to EN 60603-2 (DIN 41612)

## ESPECIFICAÇÕES

|                             |                                                                |
|-----------------------------|----------------------------------------------------------------|
| <b>Material:</b>            | Aluminio                                                       |
| <b>Acabamento:</b>          | Anodized                                                       |
| <b>Works With:</b>          | Subracks; Cases                                                |
| <b>Família de produtos:</b> | EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO |
| <b>Product Type:</b>        | Z-Rail                                                         |

Table 1/1

| Número de catálogo | Rack Width | Quantidade por embalagem | Length  | Envio rápido |
|--------------------|------------|--------------------------|---------|--------------|
| 30822-025          | 20HP       | 1                        | 101.6mm | Não          |

| Número de catálogo | Rack Width | Quantidade por embalagem | Length  | Envio rápido |
|--------------------|------------|--------------------------|---------|--------------|
| 30822-045          | 40HP       | 1                        | 203.2mm | Não          |

## DETALHES ADICIONAIS DO PRODUTO

For attaching the z-rail to the horizontal rail, both a threaded insert and Torx panhead screw are required; please order these separately.

## AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



O nosso forte portefólio de marcas:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**