

115M Standard Duty Loop Hanger



The 115M Standard Duty Loop Hanger is ideal for suspending stationary, non-insulated pipe lines, including CPVC pipes, in fire sprinkler systems. A knurled insert nut helps simplify vertical adjustments and flared edges on the base (1/2" to 4" sizes) help protect pipes from coming into contact with any sharp edges of the hanger.

CERTIFICATIONS



CARACTERÍSTICAS

Flared edges help prevent any sharp surfaces from coming into contact with the pipe (1/2" to 4" sizes)

Retained insert nut helps ensure the loop hanger and insert nut stay together

Recommended for the suspension of stationary non-insulated pipe lines

Manufactured to use the minimum rod size permitted by NFPA® for fire sprinkler piping

Conforms with Federal Specification WW-H-171 (Type 10), Manufacturers Standardization Society (MSS) SP-58 (Type 10)

ESPECIFICAÇÕES

Acabamento: Pregalvanized

Material: Aço

Table 1/2

Número de catálogo	Número do artigo	NB/DN	Diâmetro externo (OD)	Tamanho da haste (RS)	A	B
115M0050EG	597860	15	21.3 mm	M10	71 mm	28.6 mm
115M0075EG	597870	20	26.9 mm	M10	75.9 mm	30.2 mm


Número de catálogo	Número do artigo	NB/DN	Diâmetro externo (OD)	Tamanho da haste (RS)	A	B
115M0200EG	597910	50	60.3 mm	M10	108.6 mm	47.6 mm
115M0100EG	597880	25	33.7 mm	M10	82.5 mm	34.9 mm
115M0125EG	597890	32	42.4 mm	M10	90.6 mm	38.1 mm
115M0150EG	597900	40	48.3 mm	M10	96.7 mm	41.3 mm
115M0400EG	597940	100	114 mm	M10	192.5 mm	100.9 mm
115M0300EG	597930	80	89 mm	M10	166.3 mm	88.2 mm
115M0250EG	597920	65	76 mm	M10	150.8 mm	87.3 mm
115M0500EG	597950	125	140 mm	M12	232.7 mm	120 mm
115M0800EG	597970	200	219 mm	M12	327.1 mm	175.1 mm
115M0600EG	597960	150	165 mm	M12	286.6 mm	160.4 mm

Table 2/2

Número de catálogo	Número do artigo	C	Ultimate Static Load (F)	Certifications
115M0050EG	597860	25.4 mm	5000N	UL, cUL, ITB
115M0075EG	597870	23.9 mm	5000N	ITB, UL, FM Approved, Pipe Hanger Components, cUL
115M0200EG	597910	23.9 mm	5000N	ITB, UL, FM Approved, Pipe Hanger Components, cUL
115M0100EG	597880	24.1 mm	5000N	ITB, UL, FM Approved, Pipe Hanger Components, cUL
115M0125EG	597890	24.1 mm	5000N	UL, FM Approved, Pipe Hanger Components, cUL, ITB

Número de catálogo	Número do artigo	C	Ultimate Static Load (F)	Certifications
115M0150EG	597900	24.1 mm	5000N	ITB, UL, FM Approved, Pipe Hanger Components, cUL
115M0400EG	597940	48.9 mm	14000N	ITB, UL, FM Approved, Pipe Hanger Components, cUL
115M0300EG	597930	49.7 mm	14000N	ITB, UL, FM Approved, Pipe Hanger Components, cUL
115M0250EG	597920	50.8 mm	14000N	UL, FM Approved, Pipe Hanger Components, cUL, ITB
115M0500EG	597950	57.1 mm	20000N	UL, FM Approved, Pipe Hanger Components, cUL, ITB
115M0800EG	597970	73.4 mm	20000N	ITB, UL, FM Approved, Pipe Hanger Components, cUL
115M0600EG	597960	84.1 mm	20000N	ITB, UL, FM Approved, Pipe Hanger Components, cUL

DIAGRAMAS

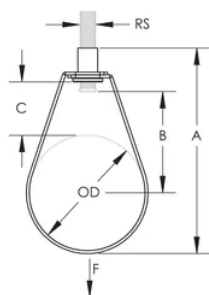

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221

Opção 1 – Apoio ao cliente

Opção 2 – Assistência
técnica

Europa

Países Baixos:

+31 800-0200135

França:

+33 800 901 793

Europa

Alemanha:

800 1890272

Outros países:

+31 13 5835404

APAC

Xangai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

