

Bar Joist Attachment



CERTIFICATIONS



CARACTERÍSTICAS

Can be installed on bar joists or I-beams

Thumb spring retainer allows for ease of positioning

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

No assembly required

No loose parts

Meets NFPA®-13 requirements for seismic sway bracing

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

ESPECIFICAÇÕES

Table 1/2

Número de catálogo	Número do artigo	Material	Acabamento	Espessura do flange (FT)	Diâmetro do parafuso (Sc)	A
CSBBARJEG	404354	Cast Iron	Electrogalvanized	6.4 - 12.7 mm	0.5	50.8 mm

Table 2/2

Número de catálogo	Número do artigo	B	C
--------------------	------------------	---	---

CSBBARJEG	404354	76.2 mm	63.5 mm
-----------	--------	---------	---------


DETALHES ADICIONAIS DO PRODUTO

Structure Attachment and Brace Member are not included.

UL Loads				
Part Number	Structure Attachment Fitting	Flange Thickness	Brace Member	Load Rating
CSBBARJ	CSBUNIV050	6 - 13 mm	DN25 - DN50 Sch. 40 NPS	4004 N
	CSBURC12	6 - 13 mm	CSB12CBL	1859 N
			CSB18CBL	3434 N
			CSB36CBL	4893 N

FM Loads					
Brace Direction	Service Pipe Size	Horizontal Capacity per Intallation Angle from Vertical			
		30° - 44°	45° - 59°	60° - 74°	75° - 90°
Parallel	N/A	6270 N	9385 N	11300 N	12590 N
Perpendicular	N/A	7740 N	7605 N	9165 N	10230 N

DIAGRAMAS

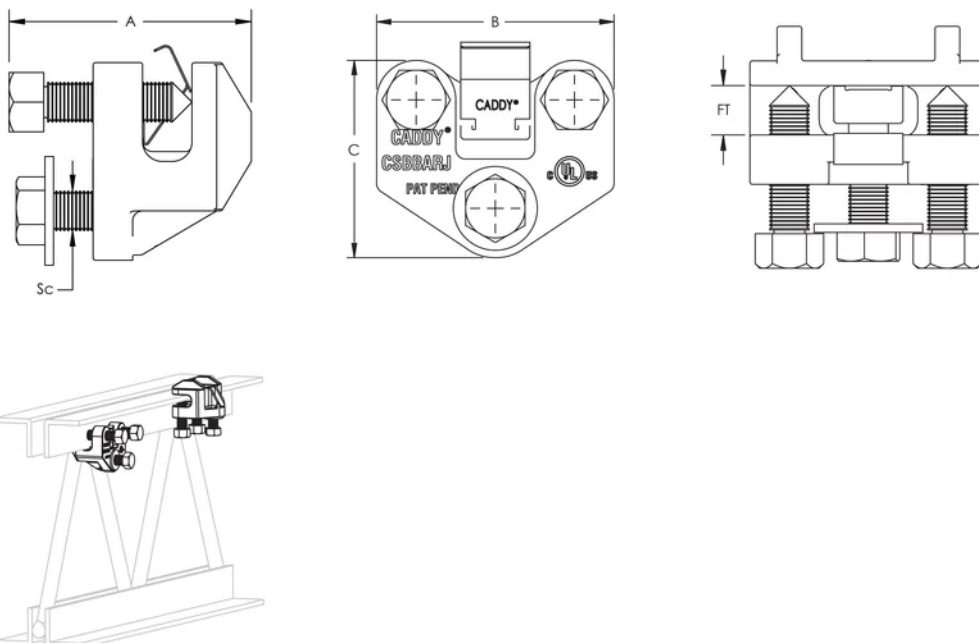

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos

representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221
Opção 1 – Apoio ao cliente
Opção 2 – Assistência
técnica

Europa

Países Baixos:
+31 800-0200135
França:
+33 800 901 793

Europa

Alemanha:
800 1890272
Outros países:
+31 13 5835404

APAC

Xangai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

