

nVent CADDY Cat HP J-Hook with Multi-Function Clip



CERTIFICATIONS



CARACTERÍSTICAS

Quick attachment to threaded rod or wire

Fully adjustable and easy to relocate to accommodate changes once installed

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Rounded edges on J-Hooks provide proper bend radius support for high performance data cables

Cost effective alternative to expensive cable tray

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

Increased capability and application options by combining 4Z and 6Z products into one enhanced and efficient offering

Improved multi-function clip allows for optimized inventory while reducing job site scheduling risks associated with multiple SKUs

ESPECIFICAÇÕES

Acabamento: Pregalvanized;nVent CADDY Armour

Table 1/2

Número de catálogo	Número do artigo	Material	Diâmetro (Ø)	Area	Cable Capacity, Cat 5e	Cable Capacity, Cat 6
CAT21HP4Z34	181258	Aço, Spring Aço	33.3 mm	1174mm ²	50	40
CAT32HP4Z34	181218	Aço, Spring Aço	50 mm	2561mm ²	90	60
CAT16HP4Z34	181217	Aço, Spring Aço	25 mm	690mm ²	20	15

Table 2/2


Número de catálogo	Número do artigo	Cable Capacity, Cat 6A	Tamanho do fio	Tamanho da haste (RS)	Static Load
CAT21HP4Z34	181258	25	3.9 - 4.8 mm	4, 6, 8, 10	130N
CAT32HP4Z34	181218	35	3.9 - 4.8 mm	4, 6, 8, 10	130N
CAT16HP4Z34	181217	10	3.9 - 4.8 mm	4, 6, 8, 10	130N

DETALHES ADICIONAIS DO PRODUTO

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

Cable capacity is calculated based on a 70% fill rate.

DIAGRAMAS

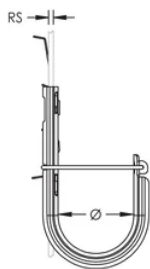

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221

Opção 1 – Apoio ao cliente

Opção 2 – Assistência
técnica

Europa

Países Baixos:

+31 800-0200135

França:

+33 800 901 793

Europa

Alemanha:

800 1890272

Outros países:

+31 13 5835404

APAC

Xangai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

