

nVent CADDY Macrofix Plus Non-Insulated



CERTIFICATIONS



CARACTERISTICAS

Increased opening angle easily accommodates all standard-sized pipes

Quick locking system prevents the hanger from accidentally opening when pipe is moved or adjusted

Quick locking system easily closes with one hand

Thread impression retains quick locking captive screw and prevents it from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

ESPECIFICAÇÕES

Acabamento: Electrogalvanized

Material: Aço

Table 1/2

Número de catálogo	Número do artigo	Diâmetro externo (OD)	Tamanho da haste (RS)	NB/DN	Largura (W)	Espessura (T)
--------------------	------------------	-----------------------	-----------------------	-------	-------------	---------------


MFZ019	586801	15 - 19 mm	M8, M10	10	20 mm	1 mm
MFZ023	586802	19 - 23 mm	M8, M10	15	20 mm	1 mm
MFZ029	586803	23 - 29 mm	M8, M10	20	20 mm	1 mm
MFZ035	586804	29 - 35 mm	M8, M10	25	20 mm	1 mm
MFZ041	586805	35 - 41 mm	M8, M10		20 mm	1 mm
MFZ048	586806	41 - 48 mm	M8, M10	32	20 mm	1 mm
MFZ055	586807	49 - 55 mm	M8, M10	40	21 mm	1.25 mm
MFZ062	586808	54 - 62 mm	M8, M10	50	21 mm	1.25 mm
MFZ072	586809	62 - 72 mm	M8, M10		21 mm	1.25 mm
MFZ083	586810	73 - 83 mm	M8, M10	65	23 mm	1.5 mm
MFZ093	586811	83 - 93 mm	M8, M10	80	23 mm	1.5 mm
MFZ103	586812	93 - 103 mm	M8, M10	90	23 mm	1.75 mm
MFZ113	586813	103 - 113 mm	M8, M10		23 mm	1.75 mm
MFZ123	586814	113 - 123 mm	M8, M10	100	23 mm	1.75 mm
MFZ133	586815	123 - 133 mm	M8, M10		23 mm	2 mm
MFZ143	586816	133 - 143 mm	M8, M10	125	23 mm	2 mm
MFZ153	586817	143 - 153 mm	M8, M10		25 mm	2 mm
MFZ165	586818	155 - 165 mm	M8, M10		25 mm	2 mm
MFZ175	586819	165 - 175 mm	M8, M10	150	25 mm	2 mm

MFZ205	586820	195 - 205 mm	M8, M10		27 mm	2.25 mm
MFZ220	586821	210 - 220 mm	M8, M10	200	27 mm	2.25 mm

Table 2/2				
Número de catálogo	Número do artigo	Diâmetro do parafuso (Sc)	Comprimento do parafuso (L)	Static Load
MFZ019	586801	6	27mm	1000N
MFZ023	586802	6	27mm	1000N
MFZ029	586803	6	32mm	1000N
MFZ035	586804	6	32mm	1000N
MFZ041	586805	6	32mm	1000N
MFZ048	586806	6	32mm	1000N
MFZ055	586807	6	32mm	1500N
MFZ062	586808	6	32mm	1500N
MFZ072	586809	6	37mm	1500N
MFZ083	586810	6	37mm	2000N
MFZ093	586811	6	37mm	2000N
MFZ103	586812	6	37mm	2500N
MFZ113	586813	6	37mm	2500N
MFZ123	586814	6	37mm	2500N
MFZ133	586815	6	40mm	3000N

Número de catálogo	Número do artigo	Diâmetro do parafuso (Sc)	Comprimento do parafuso (L)	Static Load
MFZ143	586816	6	40mm	3000N
MFZ153	586817	6	40mm	3200N
MFZ165	586818	6	40mm	3200N
MFZ175	586819	6	40mm	3200N
MFZ205	586820	6	40mm	3600N
MFZ220	586821	6	40mm	3600N

DIAGRAMAS

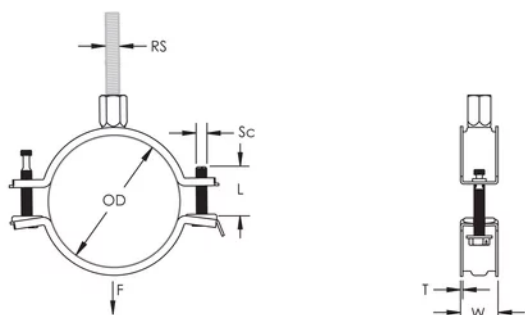

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221

Opção 1 – Apoio ao cliente

Opção 2 – Assistência
técnica

Europa

Países Baixos:

+31 800-0200135

França:

+33 800 901 793

Europa

Alemanha:

800 1890272

Outros países:

+31 13 5835404

APAC

Xangai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

