

nVent CADDY Pyramid Tool-Free Pipe Support Kit



CARACTERÍSTICAS

Push-in clamps install without the need for additional tools or strut clamps

Ready to use out of the box, saving installation time and labor

Plastic clamps and base will not corrode pipe

Clamps come in two different sizes to fit project needs

Base includes multiple holes to accommodate a variety of clamp sizes and configurations

Additional clamps can be purchased separately for additional pipe runs

Foam bottom offers low abrasion interface for better roof membrane protection

Provides superior load distribution, even with varying rooftop surfaces

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Multiple sizes and load ratings offer the ability to tailor the solution to the application

Easy to transport to the roof

ESPECIFICAÇÕES

Static Load Safety Factor: 3:1

Temperatura: -45 to 65 °C

Table 1/3

Número de catálogo	Número do artigo	Material	Comprimento 1 (L1)	Comprimento 2 (L2)	Comprimento 3 (L3)	Largura (W)
--------------------	------------------	----------	--------------------	--------------------	--------------------	-------------

PTF6	360460	Polyethylene, Polypropylene, Nylon	196 mm		81mm	150 mm
PTF10	360461	Polyethylene, Polypropylene, Nylon	318 mm	122 mm	163mm	201 mm
PTF16	360462	Polyethylene, Polypropylene, Nylon	480 mm	203 mm	244mm	201 mm

Table 2/3

Número de catálogo	Número do artigo	Altura (H)	A	B	Surface Area	Peso unitário
PTF6	360460	102 mm	122 mm	41 mm	26452mm ²	0.3 kg
PTF10	360461	102 mm	203 mm	41 mm	59355mm ²	0.5 kg
PTF16	360462	102 mm	285 mm	41 mm	91613mm ²	1 kg

Table 3/3

Número de catálogo	Número do artigo	Static Load
PTF6	360460	1330N
PTF10	360461	4450N
PTF16	360462	6670N


DETALHES ADICIONAIS DO PRODUTO

Length 2 represents maximum pipe center to pipe center using PTF2C clamps. Length 3 represents maximum pipe center to pipe center using PTF1C clamps.

Tool-Free Pipe Clamp				
Part Number	Outer Diameter OD	A	B	C
PTF1C	12.7 – 22.4 mm	9.5 mm	40.6 mm	19.1 mm
PTF2C	21.3 – 60.3 mm	9.5 mm	81.3 mm	19.1 mm

Part Number	Number of Clamps Included		Maximum Clamp Capacity	
	PTF1C	PTF2C	PTF1C	PTF2C
PTF6	1	1	3	1
PTF10	-	2	5	2
PTF16	-	2	7	3

DIAGRAMAS

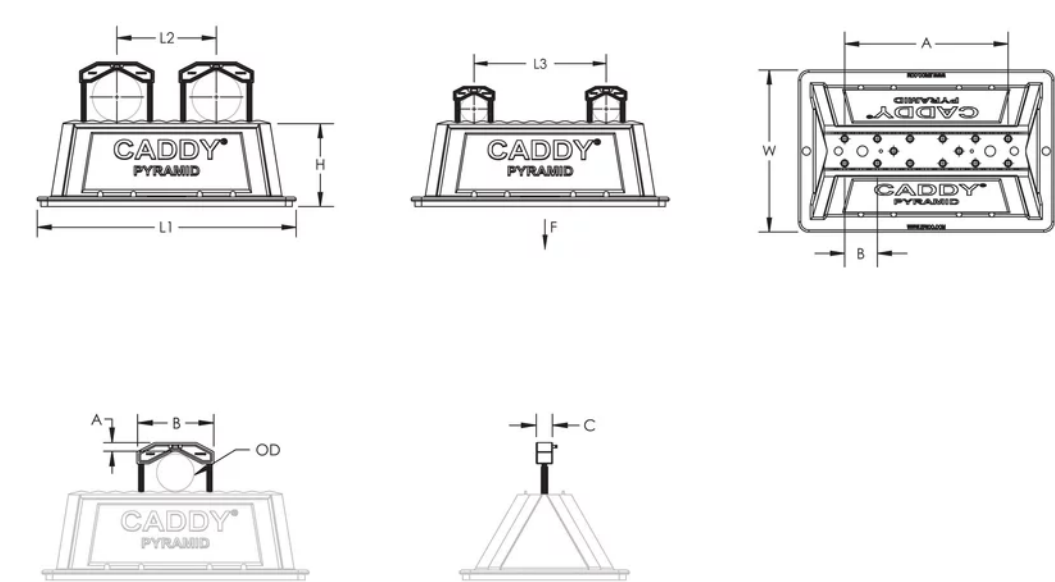

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221

Opção 1 – Apoio ao cliente

Opção 2 – Assistência
técnica

Europa

Países Baixos:

+31 800-0200135

França:

+33 800 901 793

Europa

Alemanha:

800 1890272

Outros países:

+31 13 5835404

APAC

Xangai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

