

nVent CADDY Speed Link SLK with Nail Gun Bracket



CARACTERÍSTICAS

Complete system includes wire, locking device and concrete nail gun insert bracket

Clips onto nozzle of gas or battery-actuated nail guns allowing for hands-off installation at structure or from the floor using a pole

Longer leg angle bracket for tool clearance

Quickly and easily attaches to concrete, steel or composite metal decking

ESPECIFICAÇÕES

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Acabamento:	Electrogalvanized
Em conformidade com:	SMACNA HVAC-DCS

Table 1/1

Número de catálogo	Número do artigo	Material	Wire Rope Length	A	B	Static Load
SLK15L2GBSF	197812	Steel, Liga de zinco, Polypropylene, Nylon	2m	38 mm	25.5 mm	195N
SLK15L3GBSF	197813	Steel, Liga de zinco, Polypropylene, Nylon	3m	38 mm	25.5 mm	195N


Espessura (T): 12.5 mm
Largura (W): 19 mm
Altura (H): 55 mm
Ângulo (a): 90 ° Max

DETALHES ADICIONAIS DO PRODUTO

Static Load represents the static load of the nail gun insert assembly. Please consult with the nail manufacturer to evaluate the static load of the nail and type of concrete used for the installation. Maximum load is the lesser of the static load from the nail manufacturer or the published load for the assembly.

Nail gun insert is compatible with BeA® CN60-688ES, Hilti® BX 3, GX 3, DEWALT® Trak-It C3, SPIT® PULSA 40E, 800E, 700, 1000 or equivalent nailers.

DIAGRAMAS

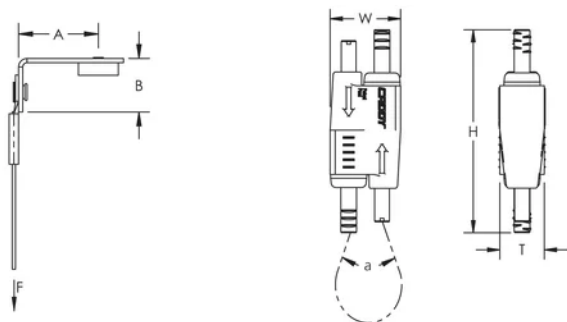

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221
Opção 1 – Apoio ao cliente
Opção 2 – Assistência
técnica

Europa

Países Baixos:
+31 800-0200135
França:
+33 800 901 793

Europa

Alemanha:
800 1890272
Outros países:
+31 13 5835404

APAC

Xangai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

