

Branch Line Restraint Pipe Attachment

Data Solutions



CERTIFICATIONS



CARACTERÍSTICAS

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

ESPECIFICAÇÕES

Acabamento: Electrogalvanized

Material: Aço


Table 1/2

Número de catálogo	Número do artigo	NB/DN	Diâmetro externo (OD)	Tamanho da haste (RS)	Altura (H)	Length (L)
--------------------	------------------	-------	-----------------------	-----------------------	------------	------------

CSBBRP0200E G	404480	50	60.3mm	10, 12	100.3mm	68.3mm
CSBBRP0125E G	404478	32	42.2mm	10, 12	82.6mm	50mm
CSBBRP0150E G	404479	40	48.3mm	10, 12	88.9mm	56.1mm
CSBBRP0100E G	404477	25	33.4mm	10, 12	73.7mm	41.4mm

Table 2/2		
Número de catálogo	Número do artigo	Largura (W)
CSBBRP0200EG	404480	22.2mm
CSBBRP0125EG	404478	22.2mm
CSBBRP0150EG	404479	22.2mm
CSBBRP0100EG	404477	22.2mm

DIAGRAMAS

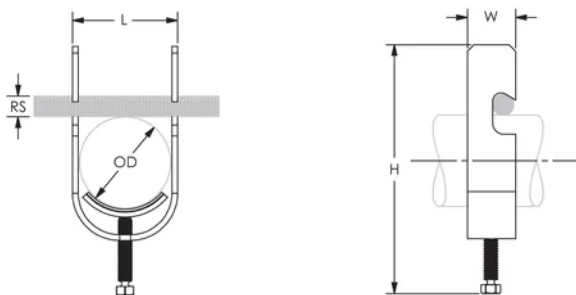

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE