


Front Panel, Refrofit Shielding, 6 U, 6 HP

Power Utilities

NÚMERO DE CATÁLOGO

20846-445

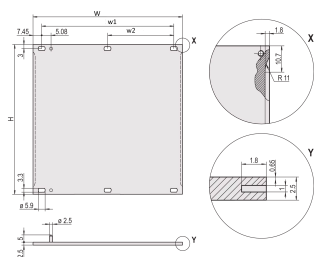

Flat front panel. Shieldable with stainless steel EMC gasket.

CERTIFICATIONS



CARACTERÍSTICAS

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

CARACTERÍSTICAS DO PRODUTO

Product Type: Front Panel

Tipo: Front Panel without Handle

Instalação: Screw-on Front

EMC Shielding: No (Retrofittable)

Gasket Type: Aço inoxidável

Material: Aluminio

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Não

Rack Height: 6 U

Altura: 261.8 mm

Rack Width: 6 HP

Largura: 30.1 mm

Em conformidade com: IEC 60297-3-101; IEEE 1101.1/10

Quantidade por embalagem: 5

DETALHES ADICIONAIS DO PRODUTO

Please order fixing material (sleeves, collar screws) separately.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE