


RackPower iPDU, RP1326, 100-240 VAC, 1-phase

Concessionárias de energia

NÚMERO DO CATÁLOGO

RP1326

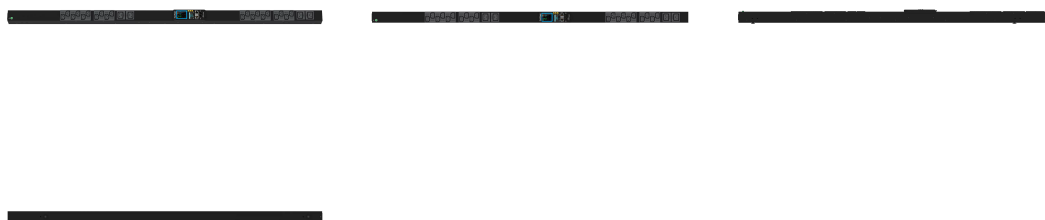

Modular, compact intelligent PDU with inlet metering. Ultra-Low Profile Design with only 44 mm height.

RECURSOS

RackPower RP1xxx Intelligent Power Distribution Units monitors input power of the entire PDU, provides billing grade unit level monitoring

High Visibility Data Display and Interactive Graphic Display

Measure circuit breaker loads across redundant feeds to avoid accidental downtime

Enables smart load balancing for power efficiency and maximized capacity utilization

Gigabit Ethernet Interface and redundant Ethernet (10/100)

iPDU DC power redundancy solution for up to 64 PDU's

Toolless Hot-Swap Controller

Input Voltage Range 100 - 240 VAC, 1-phase L-N or L-L

Input connector C20

C13, C19 outlets

ATRIBUTOS DO PRODUTO

Product Type: Socket Strip

Socket Type: IEC C13; IEC C19

Color: Preto

Length: 1490 mm

Voltage AC: 208 V

Function: Input Monitored

Depth: 53 mm

Width: 52 mm

ADDITIONAL PRODUCT DETAILS

Please order bracket for vertical mounting separately.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE