


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, SNCF

Concessionárias de energia

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

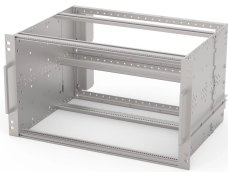

CERTIFICAÇÕES



RECURSOS

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

ESPECIFICAÇÕES

Table 1/3						
Número do catálogo	Rack Height	Rack Width	Profundidade	Package Quantity	For Mounting	Board Depth
21500-027	6 U	84 HP	320 mm	1	Backplane	220 mm
21500-029	3 U	84 HP	320 mm	1	Backplane	220 mm
21500-067	3 U	36 HP	320 mm	1	Backplane	220 mm
21500-070	6 U	36 HP	320 mm	1	Backplane	220 mm

Table 2/3						
Número do catálogo	EMC Gasket Type	Shock and Vibration Tolerance	Handle Included	Instalação	Em conformidade com	EMC Shielding
21500-027	Textile	5 g (force)	Sim	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Não
21500-029	Textile	5 g (force)	Sim	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Não
21500-067	Textile	5 g (force)	Sim	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Não
21500-070	Textile	5 g (force)	Sim	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Não

Table 3/3			
Número do catálogo	Product Type	Carga estática	Certificações
21500-027	Subrack/Chassis	15 kgf	RoHS, SNCF
21500-029	Subrack/Chassis	15 kgf	RoHS, SNCF
21500-067	Subrack/Chassis	15 kgf	RoHS

Número do catálogo	Product Type	Carga estática	Certificações
21500-070	Subrack/Chassis	15 kgf	RoHS

ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE