


Novastar Base/Plinth

Power Utilities

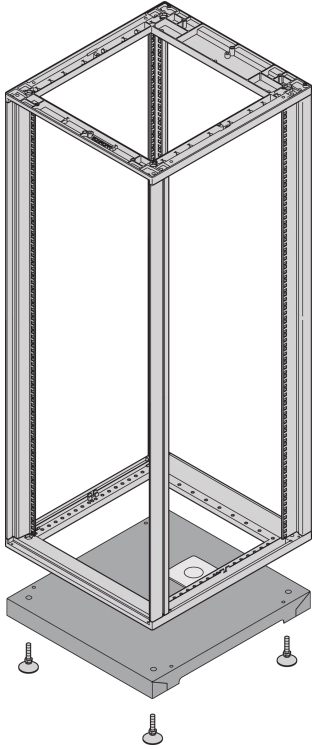

Base Plate for Rear Cable Ducting which cut out for cable management. Opening is covered with plastic. Accessory brush strip can build in.

CERTIFICATIONS



CARACTERISTICAS

Static load-carrying capacity 400 kg

Adjustable feet, height 57 mm ... 67 mm

St, 1.5 mm, RAL 7021

Cable ducting 110 x 76 mm

Incl. GND/earthing

ESPECIFICAÇÕES

Table 1/2

Número de catálogo	Largura	Profundidade	Cor	Código de cor	Altura	Product Type
27230-076	900 mm	900 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-072	553 mm	800 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-080	1000 mm	1000 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-070	553 mm	500 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-071	553 mm	600 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base

Table 2/2

Número de catálogo	Tipo
27230-076	Base Plinth
27230-072	Base Plinth
27230-080	Base Plinth
27230-070	Base Plinth
27230-071	Base Plinth

DETALHES ADICIONAIS DO PRODUTO

Please order brush strip separately.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE