


E650C-G Ground Sensor for Elexant 650c-Modbus

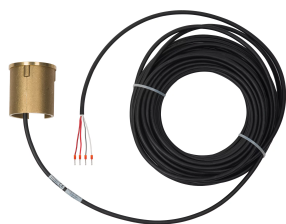

Ground sensor for combined measurement of temperature and moisture values in outdoor areas with foot or vehicle traffic. Robust version made of brass, fully encapsulated. Very low installation height, so particularly well suited to staircases, terraces, etc.

RECURSOS

Cable connection: To the side

Connection cable: 4 x 0.5 mm²

Temperature range for moisture measurement: -20°C to 30°C

ESPECIFICAÇÕES

Table 1/2

Número do catálogo	Nome do item	Comunicação	Diâmetro	Hazardous Area	Altura	Classificação IP
1244-022796	E650C-G-HOUSING	Não	68 mm	Não	31 mm	IP68
1244-022794	E650C-G	Não	68 mm	Não	72 mm	IP68

Table 2/2

Número do catálogo	Nome do item	Measuring Range
1244-022796	E650C-G-HOUSING	
1244-022794	E650C-G	-20 to 30 °C

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

Tel +1.800.545.6258

Fax +1.800.527.5703

thermal.info@nvent.com

Europe, Middle East, Africa

Tel +32.16.213.511

Fax +32.16.213.604

thermal.info@nvent.com

Asia Pacific

Tel +86.21.2412.1688

Fax +86.21.5426.3167

cn.thermal.info@nvent.com

América Latina

Tel +1.713.868.4800

Fax +1.713.868.2333

thermal.info@nvent.com

Our powerful portfolio of brands:

RAYCHEM PYROTENAX TRACER NUHEAT