


19" Pusher Fan, 3 U, Axial

Fan tray with integrated pusher fan.

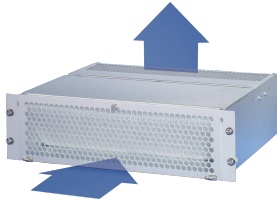

CERTIFICATIONS



CARACTERISTICAS

Ventilation directed accurately to the electronics

19" Pusher Fan, 3 U, Axial

Air infeed from front, air exits at the top rear of cabinet (guided upwards by cover plates or via hoses to rear and upwards)

Contact protection in accordance with DIN EN ISO 13857

ESPECIFICAÇÕES

Table 1/1

Número de catálogo	Tensão de entrada AC	Quantidade por embalagem	Acabamento	Material	Envio rápido
10713-546	230V	1	Aluminum-Zinc Plated	Aço, Alumínio	Não
10713-547	115V min	1	Aluminum-Zinc Plated	Aço, Alumínio	Não

DETALHES ADICIONAIS DO PRODUTO

With cover plates, this pusher fan can be re-fitted to different cooling concepts

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE