


Aisle Containment Top Cover

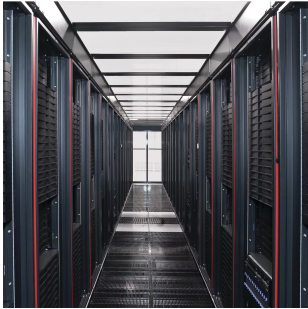

Top cover in different depths to setup a aisle containment closing.

CERTIFICATIONS



CARACTERISTICAS

Top covers to provide top cover for 2 cabinet rows

Suitable for an aisle width of 1200 mm

A top cover profile can raise the aisle height by 84 mm; please order separately

Top cover can be removed from inside (allows access to lighting and facilitates maintenance works)

ESPECIFICAÇÕES

Works With: Aisle Containment

Product Type: Cover

Table 1/2

Número de catálogo	Tipo	Largura	Profundidade	Material	Quantidade por embalagem	Cor
21130-649	Aisle Top Cover	200mm	1200mm	Aço	1	Black Grey
21130-648	Aisle Top Cover	300mm	1200mm	Aço	1	Black Grey

Número de catálogo	Tipo	Largura	Profundidade	Material	Quantidade por embalagem	Cor
21130-589	Aisle Top Cover	800mm	1200mm	Aço, Glass	1	Black Grey
21130-588	Aisle Top Cover	600mm	1200mm	Aço, Glass	1	Black Grey

Table 2/2

Número de catálogo	Código de cor	Acabamento	Certifications	Envio rápido
21130-649	RAL 7021	Pintura electrostática com Acabamento Texturado		Não
21130-648	RAL 7021	Pintura electrostática com Acabamento Texturado	RoHS	Não
21130-589	RAL 7021	Pintura electrostática com Acabamento Texturado	RoHS	Não
21130-588	RAL 7021	Pintura electrostática com Acabamento Texturado	RoHS	Não

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE