


Double Test Socket, Ø 2 mm

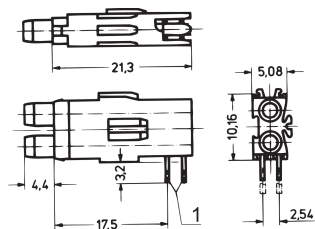

Double test sockets for mounting plane 1 and 2, short and long type.

Solder temperature should only be applied for a maximum of 5 seconds. The plastic body should be protected from the solder wave when wave soldering.

CERTIFICATIONS



CARACTERÍSTICAS

Double test sockets for Front Element System

ESPECIFICAÇÕES

Diameter: 2mm
Product Type: Socket

Table 1/2

Número de catálogo	Tipo	Quantidade por embalagem	Tensão AC	Corrente máxima	Test Voltage @ 50 Hz	Temperatura ambiente
69004-089	Long, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-131	Short, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-090	Long, Mounting Plane 2	10	30V	1A	1kV	-25 to 70°C

Table 2/2

Número de catálogo	Solder Temperature	Flammability Rating	Envio rápido
--------------------	--------------------	---------------------	--------------

69004-089	260°C	UL® 94V-0	Não
69004-131	260°C	UL® 94V-0	Não
69004-090	260°C	UL® 94V-0	Não

DETALHES ADICIONAIS DO PRODUTO

Dimensions of connecting pins: 0.3 × 0.6 mm.

Required front panel drill hole: Ø 4 mm.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE