


VME64x System, 8 U, 21 Slot, Open Frame PSU

NÚMERO DE CATÁLOGO

20836-820

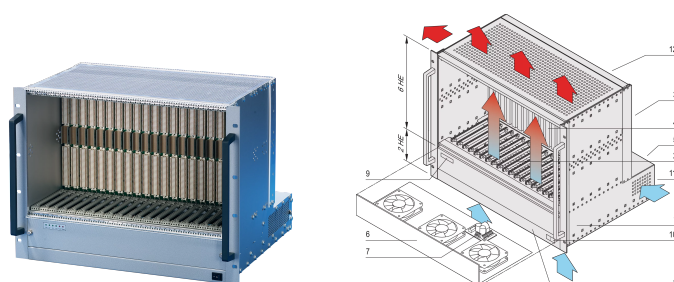

VME64 system for 21 VME64x boards 6 U, 160 mm. Rear I/O option The power for the system is supplied by a open frame power supply. A fan control module monitors the fans, the temperature and voltage.

CERTIFICATIONS



CARACTERÍSTICAS

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

PSU, open frame, 642 W (600 W at < 180 VAC)

Backplane VME64x 21 slot, 6 U, J1/J2 monolithic with P0 connector, in accordance with VITA 1-1994 and 1.1-1997

Heat dissipation by 3 fans, cooling from bottom to top; temperature-controlled by fan control module (FCM)

System for standard board mounting with board format, 6 U, 160 mm deep, Rear I / O option

Display module for DC operating voltages, fan and temperature alarm

CARATERÍSTICAS DO PRODUTO

Product Type: System

Number of Slots: 21

Tipo: 19" Rack Mount

Backplane Type: 6 U VME64 Extension

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Tensão de entrada AC: 100 – 240V

Airflow Direction: Bottom to Top

Rack Height: 8U

Power Supply Type: Open Frame

Power Supply Included: Sim

Rear I/O: Sim

Em conformidade com: ANSI/VITA 1.1-1997

Profundidade: 412mm

Altura: 354.8mm

Largura: 449mm

Power: 600W

Quantidade por embalagem: 1

DETALHES ADICIONAIS DO PRODUTO

Modified systems available on request.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE