


Front Panel, U-profile, Refrofit Shielding, 3 U, 42 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

NÚMERO DE CATÁLOGO

20848-047

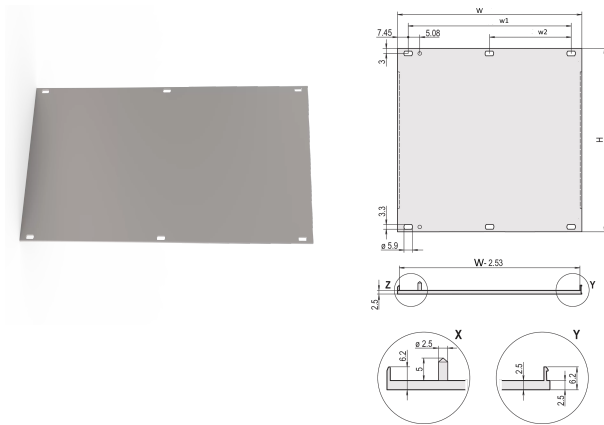

U-profile front panel for textile EMC gasket.

CERTIFICATIONS



CARACTERÍSTICAS

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

CARATERÍSTICAS DO PRODUTO

Rack Height: 3U

Rack Width: 42HP

Quantidade por embalagem: 1

Accessory Type: Front panel

Instalação: Screw-on Front

EMC Gasket Type: Textile

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Não

Em conformidade com: IEC 60297-3-101; IEEE 1101.1/10

Profundidade (D): 2.5mm

EMC Shielding: No (Retrofittable)

Acabamento: Anodized; Passivated

Altura (H): 128.4mm

Material: Alumínio

Product Type: Front Panel

Tipo: Front Panel without Handle

Largura (W): 213mm

DETALHES ADICIONAIS DO PRODUTO

Please order fixing material (sleeves, collar screws) separately.

14 ... 84 HP: multi-part U-profile (front panel with crimped profiles).


Differences in finish between 2 ... 12 HP and 14 ... 84 HP.

2 ... 12 HP: one-part U-profile

Please order textile EMC gasket separately.

Standard pack quantity: 2 to 28HP: 5 pieces, 42 to 84 HP: 1 piece, supplied in standard pack quantities (SPQ) only.

DIAGRAMAS

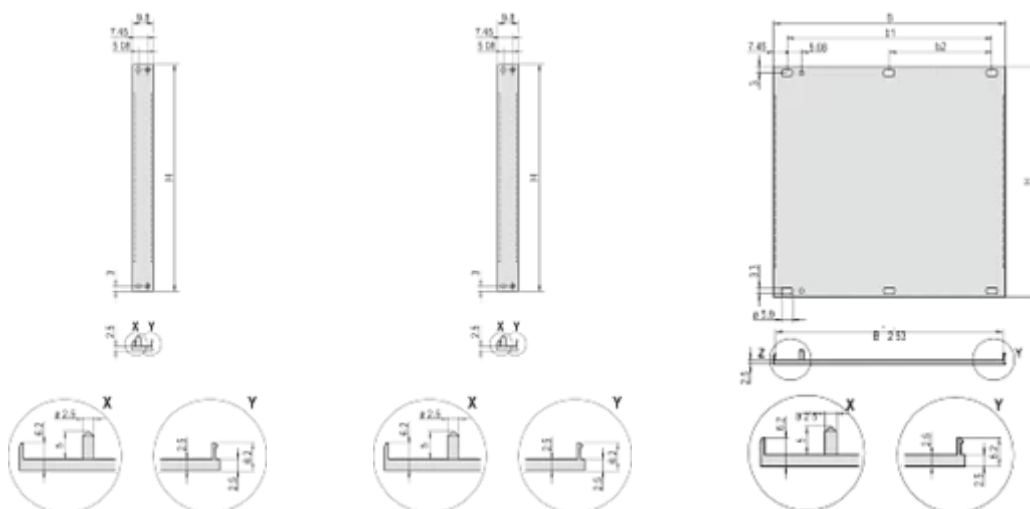

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE