 


EuropacPRO 19" Subrack Kit for Backplane, Shielded

EMC Shielded subrack for backplane mounting, rear side covered by a rear panel.



CERTIFICATIONS



CARACTERÍSTICAS

Subrack with side panel type F ("flexible"), front 19" bracket included, depth-adjustable 19" bracket sold separately (not included in items delivered)

Supplied as space-saving flat-pack

Modifications such as cutouts, different finishes or dimensions available

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

IP 20, in accordance with IEC 60529

Aluminum construction

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Rear horizontal rail for backplane mounting with insulation strip

Horizontal rail type "light"

ESPECIFICAÇÕES

Material: Alumínio

Acabamento: Anodized; Passivated

Product Type: Subrack/Chassis

EMC Shielding: Sim

Table 1/2

Número de catálogo	Rack Height	Profundidade (D)	Quantidade por embalagem	For Mounting	Board Depth	Gasket Type
24563-142	3U	235mm	1	Backplane	160mm, 220mm	Textile EMC
24563-143	3U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-144	3U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-145	3U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-146	3U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-442	6U	235mm	1	Backplane	160mm, 220mm	Textile EMC
24563-443	6U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-444	6U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-445	6U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-446	6U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC

Table 2/2


Número de catálogo	Inclui alça	Instalação	Em conformidade com	Rack Width	Static Load	Envio rápido
24563-142	Não	Rack	IEC 60297-3-103	84HP	11kg	Não
24563-143	Não	Rack	IEC 60297-3-103	84HP	11kg	Não

Número de catálogo	Inclui alça	Instalação	Em conformidade com	Rack Width	Static Load	Envio rápido
24563-144	Não	Rack	IEC 60297-3-103	84HP	11kg	Não
24563-145	Não	Rack	IEC 60297-3-103	84HP	11kg	Não
24563-146	Não	Rack	IEC 60297-3-103	84HP	11kg	Não
24563-442	Não	Rack	IEC 60297-3-103	84HP	11kg	Não
24563-443	Não	Rack	IEC 60297-3-103	84HP	11kg	Não
24563-444	Não	Rack	IEC 60297-3-103	84HP	11kg	Não
24563-445	Não	Rack	IEC 60297-3-103	84HP	11kg	Não
24563-446	Não	Rack	IEC 60297-3-103	84HP	11kg	Não

DETALHES ADICIONAIS DO PRODUTO

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

DIAGRAMAS

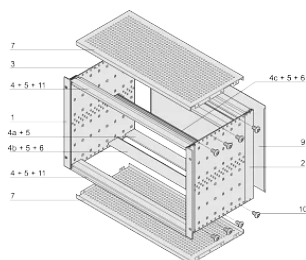

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE