



Front Panel 1 U, Horizontal Rail Mounting

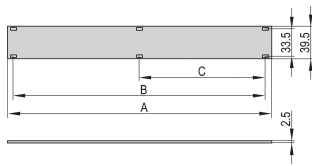

The 1 U front panel enables a user to cover the 1 U section in a 4 U PropacPRO case, RatiopacPRO 5 U (1-3-1) and EuropacPRO 4 U. The panel will be assembled to the threaded inserts of the horizontal rails.

CERTIFICATIONS

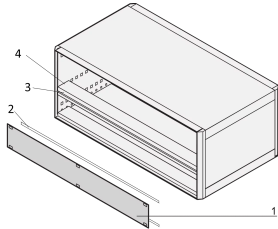

CARACTERÍSTICAS

Mounts on horizontal rails (upper, lower)

ESPECIFICAÇÕES

Material:	Aluminio
Acabamento:	Anodized; Passivated
Família de produtos:	RatiopacPRO; PropacPRO; EuropacPRO
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2


Número de catálogo	Rack Height	Altura (H)	Rack Width	Largura (W)	Profundidade (D)	Quantidade por embalagem
20850-423	1U	39.5mm	28HP	141.9mm	2.5mm	1

Número de catálogo	Rack Height	Altura (H)	Rack Width	Largura (W)	Profundidade (D)	Quantidade por embalagem
20850-425	1U	39.5mm	63HP	319.7mm	2.5mm	1
20850-426	1U	39.5mm	84HP	426.4mm	2.5mm	1
20850-424	1U	39.5mm	42HP	213mm	2.5mm	1

Table 2/2

Número de catálogo	Front Finish	Rear Finish	Treated Edges	Envio rápido
20850-423	Anodized	Conductive	Não	Não
20850-425	Anodized	Conductive	Não	Não
20850-426	Anodized	Conductive	Não	Não
20850-424	Anodized	Conductive	Não	Não

DIAGRAMAS

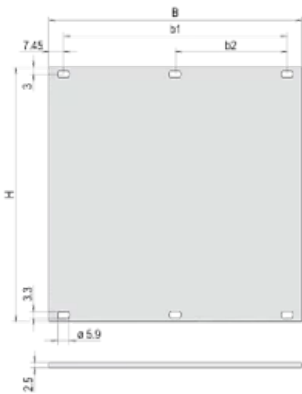

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE