

Front Panel, Anodized, Unshielded, Screw Assembly

Anodized front panel, unshielded version, Al, 2.5 mm.



CERTIFICATIONS



CARACTERISTICAS

Partial width front panel, Al, 2.5 mm

Al, anodized

ESPECIFICAÇÕES

Profundidade (D):	2.5mm
Material:	Aluminio
Acabamento:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel
Tipo:	Front Panel without Handle

Table 1/3

Número de catálogo	Rack Height	Rack Width	Quantidade por embalagem	Instalação	Front Finish	Rear Finish
30807-508	3U	3HP	1	Screw-on Front	Anodized	Anodized

Número de catálogo	Rack Height	Rack Width	Quantidade por embalagem	Instalação	Front Finish	Rear Finish
30807-481	3U	4HP	1	Screw-on Front	Anodized	Anodized
30818-741	6U	2HP	1	Screw-on Front	Anodized	Anodized
30807-510	3U	5HP	1	Screw-on Front	Anodized	Anodized
30807-482	3U	6HP	1	Screw-on Front	Anodized	Anodized
30807-509	3U	7HP	1	Screw-on Front	Anodized	Anodized
30807-484	3U	8HP	1	Screw-on Front	Anodized	Anodized
30807-483	3U	10HP	1	Screw-on Front	Anodized	Anodized
30807-777	6U	5HP	1	Screw-on Front	Anodized	Anodized
30807-485	3U	12HP	1	Screw-on Front	Anodized	Anodized
30807-752	6U	6HP	1	Screw-on Front	Anodized	Anodized
30807-501	3U	14HP	1	Screw-on Front	Anodized	Anodized
30807-833	6U	7HP	1	Screw-on Front	Anodized	Anodized
30807-779	6U	8HP	1	Screw-on Front	Anodized	Anodized
30807-487	3U	21HP	1	Screw-on Front	Anodized	Anodized
30807-753	6U	10HP	1	Screw-on Front	Anodized	Anodized
30807-755	6U	12HP	1	Screw-on Front	Anodized	Anodized
30807-496	3U	28HP	1	Screw-on Front	Anodized	Anodized
30807-758	6U	14HP	1	Screw-on Front	Anodized	Anodized

Número de catálogo	Rack Height	Rack Width	Quantidade por embalagem	Instalação	Front Finish	Rear Finish
30807-780	6U	16HP	1	Screw-on Front	Anodized	Anodized
30807-494	3U	42HP	1	Screw-on Front	Anodized	Anodized
30807-757	6U	21HP	1	Screw-on Front	Anodized	Anodized
30807-416	2U	84HP	1	Screw-on Front	Anodized	Anodized
30807-766	6U	28HP	1	Screw-on Front	Anodized	Anodized
30808-067	3U	63HP	1	Screw-on Front	Anodized	Anodized
30807-506	3U	84HP	1	Screw-on Front	Anodized	Anodized
30807-764	6U	42HP	1	Screw-on Front	Anodized	Anodized
30807-596	4U	84HP	1	Screw-on Front	Anodized	Anodized
30807-771	6U	63HP	1	Screw-on Front	Anodized	Anodized
30807-776	6U	84HP	1	Screw-on Front	Anodized	Anodized
30807-778	6U	4HP	1	Screw-on Front	Anodized	Anodized
30810-432	3U	2HP	1	Screw-on Front	Anodized	Anodized

Table 2/3

Número de catálogo	Treated Edges	Em conformidade com	EMC Shielding	Altura (H)	Largura (W)	Certifications
30807-508	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	14.9mm	RoHS
30807-481	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	20mm	RoHS

Número de catálogo	Treated Edges	Em conformidade com	EMC Shielding	Altura (H)	Largura (W)	Certifications
30818-741	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	9.8mm	RoHS
30807-510	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	25mm	RoHS
30807-482	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	30.1mm	RoHS
30807-509	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	35.2mm	RoHS
30807-484	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	40.3mm	RoHS
30807-483	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	50.5mm	RoHS
30807-777	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	25mm	RoHS
30807-485	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	60.6mm	RoHS
30807-752	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	30.1mm	RoHS
30807-501	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	70.8mm	RoHS
30807-833	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	35.2mm	RoHS
30807-779	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	40.3mm	RoHS
30807-487	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	106.3mm	RoHS
30807-753	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	50.5mm	RoHS

Número de catálogo	Treated Edges	Em conformidade com	EMC Shielding	Altura (H)	Largura (W)	Certifications
30807-755	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	60.6mm	RoHS
30807-496	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	141.9mm	RoHS
30807-758	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	70.8mm	RoHS
30807-780	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	80.9mm	RoHS
30807-494	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	213mm	RoHS
30807-757	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	106.3mm	RoHS
30807-416	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	84mm	426.4mm	RoHS
30807-766	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	141.9mm	RoHS
30808-067	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	319.7mm	RoHS
30807-506	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	426.4mm	RoHS
30807-764	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	213mm	RoHS
30807-596	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	172.9mm	426.4mm	
30807-771	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	319.7mm	RoHS
30807-776	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	426.4mm	RoHS

Número de catálogo	Treated Edges	Em conformidade com	EMC Shielding	Altura (H)	Largura (W)	Certifications
30807-778	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	261.8mm	20mm	RoHS
30810-432	Sim	IEC 60297-3-101, IEEE 1101.1/10	Não	128.4mm	9.8mm	RoHS

Table 3/3


Número de catálogo	Envio rápido
30807-508	Não
30807-481	Não
30818-741	Não
30807-510	Não
30807-482	Não
30807-509	Não
30807-484	Não
30807-483	Não
30807-777	Não
30807-485	Não
30807-752	Não
30807-501	Não
30807-833	Não
30807-779	Não

Número de catálogo	Envio rápido
30807-487	Não
30807-753	Não
30807-755	Não
30807-496	Não
30807-758	Não
30807-780	Não
30807-494	Não
30807-757	Não
30807-416	Não
30807-766	Não
30808-067	Não
30807-506	Não
30807-764	Não
30807-596	Não
30807-771	Não
30807-776	Não
30807-778	Não
30810-432	Não

DETALHES ADICIONAIS DO PRODUTO

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMAS

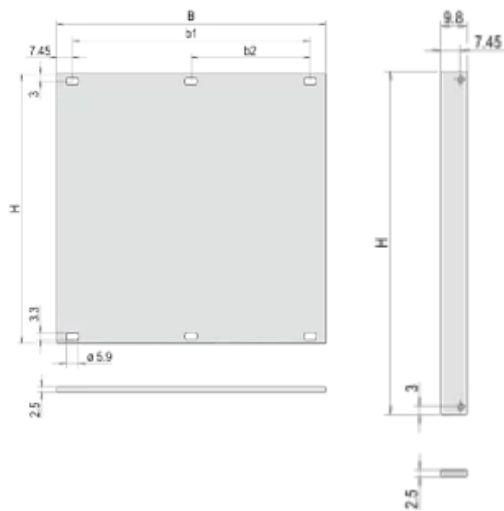

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE