


Plug-In Unit U-Profile Front Panel for XL Handle

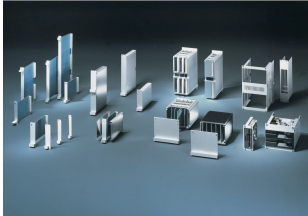

Front panel for XL handle. Shieldable with textile gasket. with or without cutout for a microswitch.

CERTIFICATIONS



CARACTERÍSTICAS

Al, front anodized, sides and rear conductive

Suitable for sleeve and collar screw

U-front profile, shieldable, for inserter/extractor handle, type XL

ESPECIFICAÇÕES

Material:	Aluminio
Acabamento:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Tipo:	Front Panel for Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Número de catálogo	Rack Width	Quantidade por embalagem	Tipo de alça	Instalação	Gasket Type	Front Finish
30849-153	4HP	1	XL	Screw-on Front	Textile EMC	Anodized

Número de catálogo	Rack Width	Quantidade por embalagem	Tipo de alça	Instalação	Gasket Type	Front Finish
30849-154	4HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-156	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-155	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-158	12HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-157	12HP	1	XL	Screw-on Front	Textile EMC	Anodized

Table 2/3

Número de catálogo	Rear Finish	Treated Edges	Em conformidade com	Profundidade (D)	Altura (H)	Rack Height
30849-153	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-154	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-156	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-155	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-158	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-157	Conductive	Não	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U

Table 3/3

Número de catálogo	Largura (W)	Envio rápido
30849-153	20mm	Não
30849-154	20mm	Não

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE