


# Socket Strip, IEC C13

Modular, compact PDU with many function elements. Using a 1 U by 1 U aluminum chassis the PDU can easily be integrated in a rack with IEC C13 outlets.

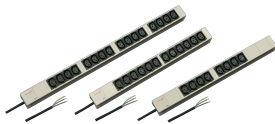

## CERTIFICATIONS



## CARACTERISTICAS

230 V, 10 A

Horizontal and vertical mounting

Socket strips can be rotated through all four directions (in 90° increments) during installation

Socket strips with IEC 60320-C13 sockets

Connecting cable 2 m, open end with ferrules

In accordance with IEC 60320

Mounting height 1 U

## ESPECIFICAÇÕES

**Material:** Alumínio; Polyamide

**Cor:** Grey

**Product Type:** Socket Strip

Table 1/2

| Número de catálogo | Tipo de soquete | Socket Quantity | Switched Outlets | Tensão AC | Quantidade por embalagem | Profundidade |
|--------------------|-----------------|-----------------|------------------|-----------|--------------------------|--------------|
|--------------------|-----------------|-----------------|------------------|-----------|--------------------------|--------------|

|           |         |    |     |      |   |      |
|-----------|---------|----|-----|------|---|------|
| 60110-290 | IEC C13 | 8  | Não | 230V | 1 | 44mm |
| 60110-291 | IEC C13 | 12 | Não | 230V | 1 | 44mm |
| 60110-292 | IEC C13 | 16 | Não | 230V | 1 | 44mm |

| Table 2/2          |            |         |              |
|--------------------|------------|---------|--------------|
| Número de catálogo | Acabamento | Length  | Envio rápido |
| 60110-290          | Anodized   | 438.5mm | Não          |
| 60110-291          | Anodized   | 438.5mm | Não          |
| 60110-292          | Anodized   | 608.5mm | Não          |

## DETALHES ADICIONAIS DO PRODUTO

Please order bracket for vertical mounting separately.

## AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



O nosso forte portefólio de marcas:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**