


Varistar CP 19" Panel/Slide Mount

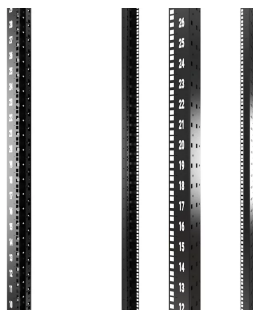

Slide mount with adjustable increments. Assembly in 600 mm wide cabinets directly on the frame. At 800 mm width adapter bracket for reduced width is necessary, for partial-height mounting depth members are necessary.

CARACTERISTICAS

19" panel/slide mount with U indicator

Depth-adjustable in 25 mm increments

In accordance with IEC 60297-1 (DIN 41 494, Part 1)

ESPECIFICAÇÕES

Acabamento: Pintura electrostática com Acabamento Texturado

Product Type: Slide Mount

Material: Aço

Table 1/1

Número de catálogo	Rack Height	Altura	Quantidade por embalagem	Cor	Código de cor	Envio rápido
24630-013	42U	2000mm	4	Jet Black	RAL 9005	Não
24630-015	52U	2450mm	4	Jet Black	RAL 9005	Não
24630-014	47U	2200mm	4	Jet Black	RAL 9005	Não

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha

qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE