


Varistar Mounting Plate

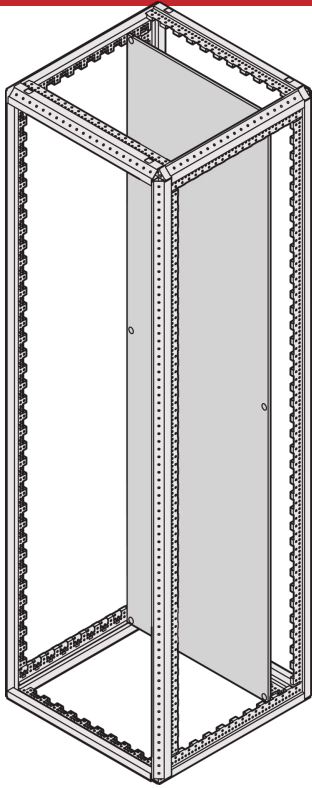

Varistar Mounting Plate for mounting electrical components and sub-assemblies, with 600 kg load capacity. The mounting plate can also be rear mounted and strengthening bracket can be added to increase load capacity.

CERTIFICATIONS



CARACTERISTICAS

For mounting electrical components and sub-assemblies including cabling

Mounting pitch 25 mm in depth and 50 mm in height for partial-height mounting

Static load-carrying capacity up to 450 kg (rear mounted)

600 kg at full height, mounted to rear, with additional strengthening brackets

Strengthening bracket increases static load-carrying capacity

ESPECIFICAÇÕES

Product Type: Mounting Plate
Material: Aço

Table 1/1					
Número de catálogo	Altura	Largura	Quantidade por embalagem	Acabamento	Envio rápido
23130-405	1800mm	600mm	1	Chapa de Aço Zincada	Não
23130-414	1200mm	800mm	1	Chapa de Aço Zincada	Não
23130-413	1200mm	600mm	1	Chapa de Aço Zincada	Não
23130-408	2000mm	800mm	1	Chapa de Aço Zincada	Não
23130-406	1800mm	800mm	1	Chapa de Aço Zincada	Não
23130-407	2000mm	600mm	1	Chapa de Aço Zincada	Não

DETALHES ADICIONAIS DO PRODUTO

Depth members are required for partial-height mounting.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE