

4G16H Twist Clip with 90° Plain Hole



CERTIFICATIONS



CARACTERISTICI

Provides an attachment for nVent CADDY Speed Link assemblies, wire, S-hooks, or chain from T-Grid

Fast, easy and secure twist-on installation

No tools required for installation

SPECIFICAȚII

Material: Spring Steel

Table 1/2


Număr de catalog	Article Number	Finish	Color	Hole Size (HS)	Flange Thickness (FT)	T-Grid Size
4G16H	170230	nVent CADDY Armour	Gray	6.4 mm	1.5 mm Max	24mm
4G16HWH	576950	Painted	White	6.4 mm	1.5 mm Max	24mm

Table 2/2

Număr de catalog	Article Number	Static Load
------------------	----------------	-------------

4G16H	170230	180N
4G16HWH	576950	180N

DIAGRAMS

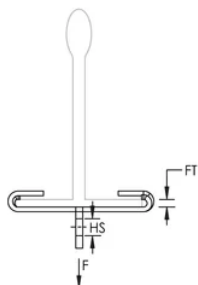

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

