

Bar Joist Attachment



CERTIFICATIONS



CARACTERISTICI

Can be installed on bar joists or I-beams

Thumb spring retainer allows for ease of positioning

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

No assembly required

No loose parts

Meets NFPA®-13 requirements for seismic sway bracing

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

SPECIFICAȚII

Table 1/2

Număr de catalog	Article Number	Material	Finish	Flange Thickness (FT)	Screw Diameter (Sc)	A
CSBBARJEG	404354	Cast Iron	Electrogalvanized	6.4 - 12.7 mm	0.5	50.8 mm

Table 2/2

Număr de catalog	Article Number	B	C
------------------	----------------	---	---

CSBBARJEG	404354	76.2 mm	63.5 mm
-----------	--------	---------	---------


DETALII SUPLIMENTARE DESPRE PRODUS

Structure Attachment and Brace Member are not included.

UL Loads				
Part Number	Structure Attachment Fitting	Flange Thickness	Brace Member	Load Rating
CSBBARJ	CSBUNIV050	6 - 13 mm	DN25 - DN50 Sch. 40 NPS	4004 N
	CSBURC12	6 - 13 mm	CSB12CBL	1859 N
			CSB18CBL	3434 N
			CSB36CBL	4893 N

FM Loads					
Brace Direction	Service Pipe Size	Horizontal Capacity per Intallation Angle from Vertical			
		30° - 44°	45° - 59°	60° - 74°	75° - 90°
Parallel	N/A	6270 N	9385 N	11300 N	12590 N
Perpendicular	N/A	7740 N	7605 N	9165 N	10230 N

DIAGRAMS

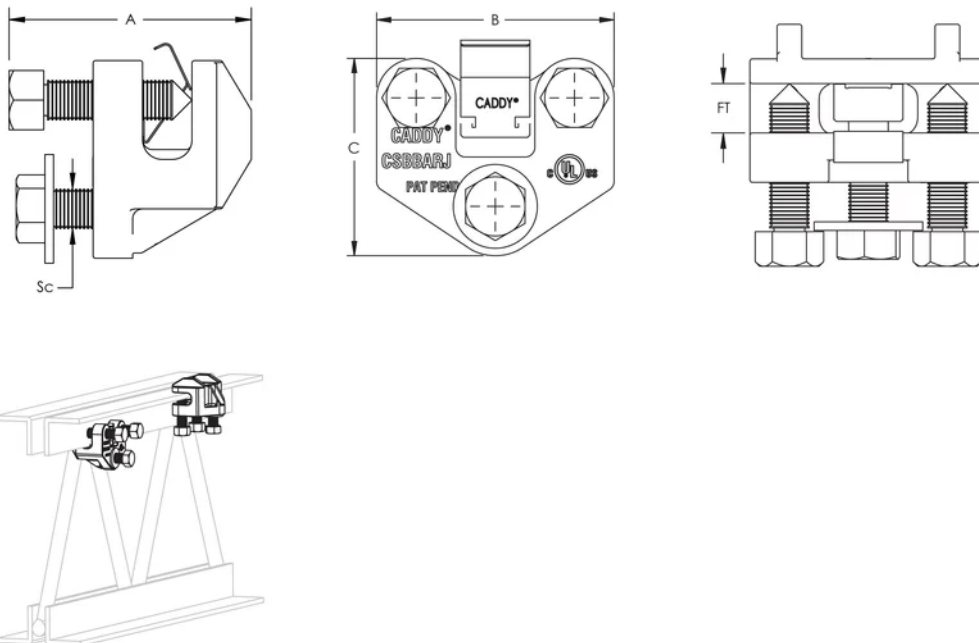

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O

instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

