

Cable/Conduit to Wire Clip



CERTIFICATIONS



CARACTERISTICI

Supports cable and conduit without bending drop wire

Faster installation than traditional methods

SPECIFICAȚII

Finish: nVent CADDY Armour

Material: Spring Steel


Table 1/1

Număr de catalog	Article Number	Outer Diameter (OD)	Wire Size	Hole Size (HS)	Ultimate Static Load (F)	Certifications
PCS2	170881	15 - 23 mm	2 - 4 mm	6.8 mm	110N	ITB
PCS1	170880	11 - 14 mm	2 - 4 mm	6.8 mm	110N	cUL, UL, ITB

DETALII SUPLIMENTARE DESPRE PRODUS

NEC® 300.11 requires dedicated drop wire/rod and EC311.

DIAGRAMS

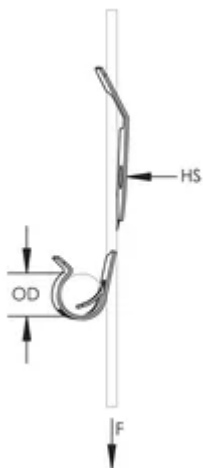

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

