

Cantilever Arm with E4 Channel



CERTIFICATIONS



CARACTERISTICI

Perforated, cold rolled

Slotted backplate

SPECIFICAȚII

Finish: Electrogalvanized

Material: Oțel


Table 1/1

Număr de catalog	Article Number	Length (L)
CE420H0200EG	599935	200mm
CE420H0300EG	599950	300mm
CE420H0350EG	599960	350mm

Număr de catalog	Article Number	Length (L)
CE420H0450EG	599970	450mm
CE420H0550EG	599980	550mm
CE420H0650EG	599990	650mm
CE420H0800EG	599995	800mm

Thickness (T): 2 mm
E: 6 mm
X: 11 x 18 mm
Y: 14 x 27 mm
C: 15.5 mm
B: 38 mm
Width (W): 40 mm
A: 40 mm
D: 50 mm
Height (H): 120 mm

DIAGRAMS

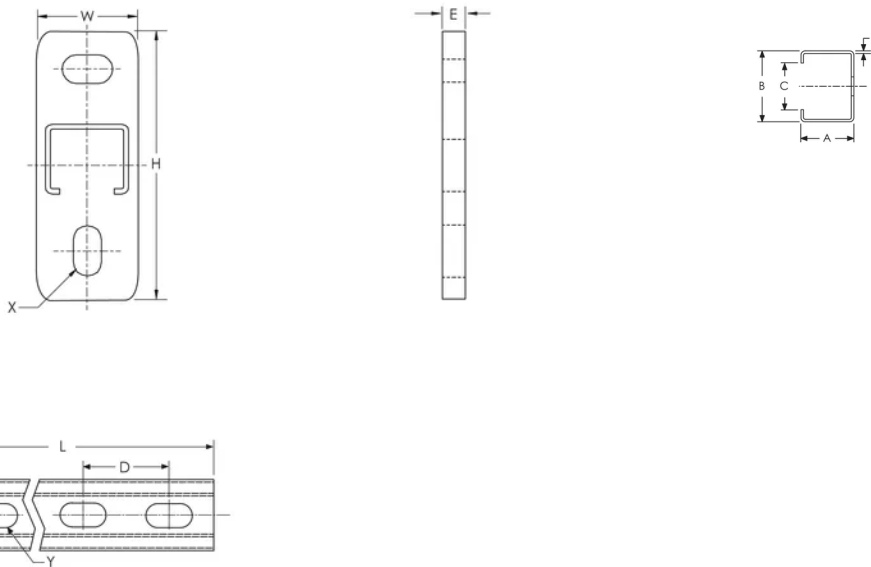

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O

instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

