 


ECN Nut for C-Channel E0/E0L/E1



CARACTERISTICI

Channel nut for C-Profiles

SPECIFICAȚII

Finish: Electrogalvanized

Material: Oțel

Table 1/1


Număr de catalog	Article Number	Channel Type	Rod Size (RS)	Thickness (T)	A	B
E01CNM6	315370	E0, E0L, E1	6	4 mm	23 mm	14 mm
E01CNM8	315340	E0, E0L, E1	8	4 mm	23 mm	14 mm
E01CNM10	315350	E0, E0L, E1	10	4 mm	23 mm	14 mm

DETALII SUPLIMENTARE DESPRE PRODUS

Sliding force F2 is limited to 600 N for all types of Nuts and T-Bolts for C-channel System.

Nuts and T-Bolts for C-channel System	
C-Channel Type	Pullout Force F1
E0	1000 N
E0L	1000 N
E1	1600 N

DIAGRAMS

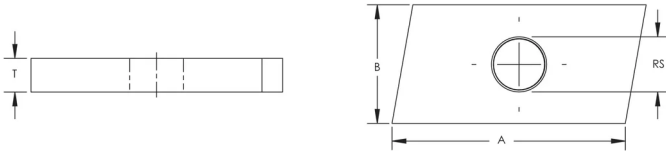

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

