

nVent CADDY Cat HP J-Hook with Multi-Function Clip



CERTIFICATIONS



CARACTERISTICI

Quick attachment to threaded rod or wire

Fully adjustable and easy to relocate to accommodate changes once installed

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Rounded edges on J-Hooks provide proper bend radius support for high performance data cables

Cost effective alternative to expensive cable tray

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

Increased capability and application options by combining 4Z and 6Z products into one enhanced and efficient offering

Improved multi-function clip allows for optimized inventory while reducing job site scheduling risks associated with multiple SKUs

SPECIFICAȚII

Finish: Pregalvanized; nVent CADDY Armour

Table 1/2

Număr de catalog	Article Number	Material	Diameter (Ø)	Area	Cable Capacity, Cat 5e	Cable Capacity, Cat 6
CAT21HP4Z34	181258	Oțel, Spring Oțel	33.3 mm	1174mm ²	50	40
CAT32HP4Z34	181218	Oțel, Spring Oțel	50 mm	2561mm ²	90	60
CAT16HP4Z34	181217	Oțel, Spring Oțel	25 mm	690mm ²	20	15

Table 2/2


Număr de catalog	Article Number	Cable Capacity, Cat 6A	Wire Size	Rod Size (RS)	Static Load
CAT21HP4Z34	181258	25	3.9 - 4.8 mm	4, 6, 8, 10	130N
CAT32HP4Z34	181218	35	3.9 - 4.8 mm	4, 6, 8, 10	130N
CAT16HP4Z34	181217	10	3.9 - 4.8 mm	4, 6, 8, 10	130N

DETALII SUPLIMENTARE DESPRE PRODUS

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

Cable capacity is calculated based on a 70% fill rate.

DIAGRAMS

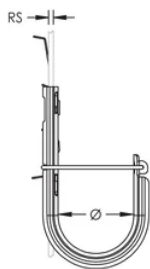

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

