

nVent CADDY Macrofix Plus NI EZ with Easy Closure



CERTIFICATIONS



CARACTERISTICI

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

SPECIFICAȚII

Finish: Electrogalvanized

Material: Oțel


Table 1/2

Număr de catalog	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Width (W)	Thickness (T)
MPZ040	595056	32	40.0 - 42.4 mm	M10	30 mm	1.5 mm
MPZ025	595053	20	25.0 - 26.9 mm	M10	30 mm	1.5 mm
MPZ032	595054	25	32.0 - 33.7 mm	M10	30 mm	1.5 mm
MPZ020	595052	15	20.0 - 21.3 mm	M10	30 mm	1.5 mm
MPZ050	595057	40	48.3 - 50 mm	M10	30 mm	2 mm
MPZ075	595061	65	75.0 - 76.1 mm	M10	30 mm	2 mm
MPZ063	595059	50	60.3 - 63 mm	M10	30 mm	2 mm

Table 2/2

Număr de catalog	Article Number	Static Load	Certifications
MPZ040	595056	1125N	AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components
MPZ025	595053	1125N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ
MPZ032	595054	1125N	AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components
MPZ020	595052	1125N	AON Fire Protection, BB019, pipe hangers
MPZ050	595057	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ075	595061	1725N	
MPZ063	595059	1725N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ

DIAGRAMS

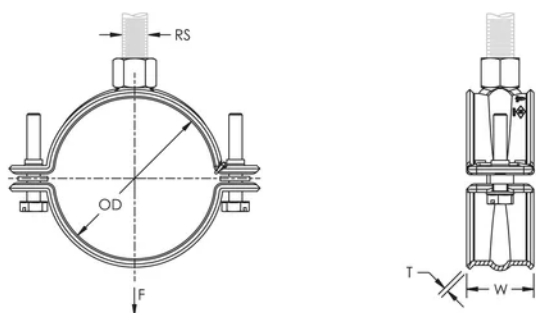

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

