

# nVent CADDY Pyramid Light-Duty Equipment Support Kit Extension Frame



The nVent CADDY Pyramid Light-Duty Equipment Support Kit Extension Frame provides an efficient way to link HVAC units together. Pairing with the nVent CADDY Pyramid Light-Duty Equipment Support Kit creates an innovative system that allows contractors to quickly and easily install HVAC mini split units on rooftops. To further increase overall productivity, savings and job site safety, opt to pre-assemble the system beforehand.

## CARACTERISTICI

System takes 80% less time to install than using other standard options on the market

Easily adjusts from 12 -18 in (305 -457 mm), reducing the need for multiple SKUs

Increased adjustability enables flexibility to move bars, sliding the kit as needed

Extension Kit allows for pre-assembly and endless gang-ability of units linked together

Extension Kit is 8.4 in (213 mm) longer than four-post kit to allow for mounted equipment to be serviced in place

Evenly distributes load and avoids damaging roof membrane with nVent CADDY PEK-style foam bottom feet

Product load rating can handle a wide range of equipment BTU outputs/sizes

Hot dip galvanized construction and hardware provide superior corrosion resistance in demanding environments

## SPECIFICAȚII

Table 1/3

| Număr de catalog | Article Number | Material | Finish             | Temperature      | Height (H)   | Length (L) |
|------------------|----------------|----------|--------------------|------------------|--------------|------------|
| PEKLDEF          | 360531         | Oțel     | Hot-Dip Galvanized | -34.4 to 54.4 °C | 305 - 457 mm | 1265mm     |


Table 2/3

| Număr de catalog | Article Number | Post Base (A) | Square Tube (B)   | Cross Bar Assembly (C) | Width (W) | Surface Area        |
|------------------|----------------|---------------|-------------------|------------------------|-----------|---------------------|
| PEKLDEF          | 360531         | 152 mm x 2 pc | 1224.28 mm x 2 pc | 521 mm x 2 pc          | 660 mm    | 0.046m <sup>2</sup> |

Table 3/3

| Număr de catalog | Article Number | Unit Weight | Ultimate Static Load (F) | Static Load Safety Factor |
|------------------|----------------|-------------|--------------------------|---------------------------|
| PEKLDEF          | 360531         | 11.5 kg     | 1779N                    | 3:1                       |

## DIAGRAMS

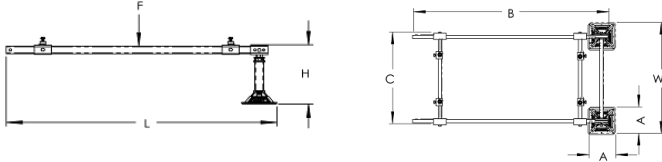

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

