

nVent CADDY Pyramid Tool-Free Cable Tray Support Kit



CARACTERISTICI

Push-in pins install without the need for additional tools

Plastic pins and base will not corrode

Pins and mounting holes accommodate most perforated cable tray

Ready to use out of the box, saving installation time and labor

Additional pins can be purchased separately

Foam bottom offers low abrasion interface for better roof membrane protection

Provides superior load distribution, even with varying rooftop surfaces

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Multiple sizes and load ratings offer the ability to tailor the solution to the application

Easy to transport to the roof

SPECIFICAȚII

Static Load Safety Factor: 3:1

Temperature: -45 to 65 °C

Table 1/2


Număr de catalog	Article Number	Material	Length (L)	Width (W)	Height (H)	Surface Area
PTF6P	360518	Polyethylene, Polypropylene, Nylon	196mm	150 mm	102 mm	26452mm ²

Număr de catalog	Article Number	Material	Length (L)	Width (W)	Height (H)	Surface Area
PTF10P	360519	Polyethylene, Polypropylene, Nylon	318mm	201 mm	102 mm	59355mm ²
PTF16P	360522	Polyethylene, Polypropylene, Nylon	480mm	201 mm	102 mm	91613mm ²

Table 2/2

Număr de catalog	Article Number	Unit Weight	Static Load
PTF6P	360518	0.3 kg	1330N
PTF10P	360519	0.5 kg	4450N
PTF16P	360522	1 kg	6670N

DIAGRAMS

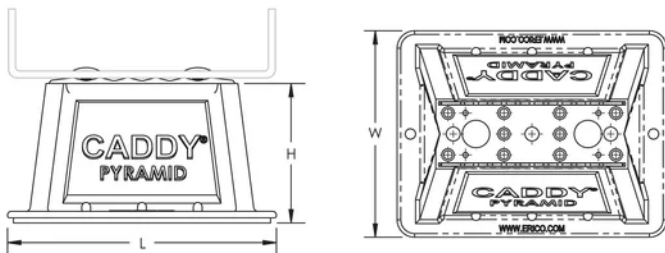

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

