

nVent CADDY Pyramid Tool-Free Pipe Support Kit



CARACTERISTICI

Push-in clamps install without the need for additional tools or strut clamps

Ready to use out of the box, saving installation time and labor

Plastic clamps and base will not corrode pipe

Clamps come in two different sizes to fit project needs

Base includes multiple holes to accommodate a variety of clamp sizes and configurations

Additional clamps can be purchased separately for additional pipe runs

Foam bottom offers low abrasion interface for better roof membrane protection

Provides superior load distribution, even with varying rooftop surfaces

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Multiple sizes and load ratings offer the ability to tailor the solution to the application

Easy to transport to the roof

SPECIFICAȚII

Static Load Safety Factor: 3:1

Temperature: -45 to 65 °C

Table 1/3

Număr de catalog	Article Number	Material	Length 1 (L1)	Length 2 (L2)	Length 3 (L3)	Width (W)
------------------	----------------	----------	---------------	---------------	---------------	-----------

PTF6	360460	Polyethylene, Polypropylene, Nylon	196 mm		81mm	150 mm
PTF10	360461	Polyethylene, Polypropylene, Nylon	318 mm	122 mm	163mm	201 mm
PTF16	360462	Polyethylene, Polypropylene, Nylon	480 mm	203 mm	244mm	201 mm

Table 2/3

Număr de catalog	Article Number	Height (H)	A	B	Surface Area	Unit Weight
PTF6	360460	102 mm	122 mm	41 mm	26452mm ²	0.3 kg
PTF10	360461	102 mm	203 mm	41 mm	59355mm ²	0.5 kg
PTF16	360462	102 mm	285 mm	41 mm	91613mm ²	1 kg

Table 3/3

Număr de catalog	Article Number	Static Load
PTF6	360460	1330N
PTF10	360461	4450N
PTF16	360462	6670N


DETALII SUPLIMENTARE DESPRE PRODUS

Length 2 represents maximum pipe center to pipe center using PTF2C clamps. Length 3 represents maximum pipe center to pipe center using PTF1C clamps.

Tool-Free Pipe Clamp				
Part Number	Outer Diameter OD	A	B	C
PTF1C	12.7 – 22.4 mm	9.5 mm	40.6 mm	19.1 mm
PTF2C	21.3 – 60.3 mm	9.5 mm	81.3 mm	19.1 mm

Part Number	Number of Clamps Included		Maximum Clamp Capacity	
	PTF1C	PTF2C	PTF1C	PTF2C
PTF6	1	1	3	1
PTF10	-	2	5	2
PTF16	-	2	7	3

DIAGRAMS

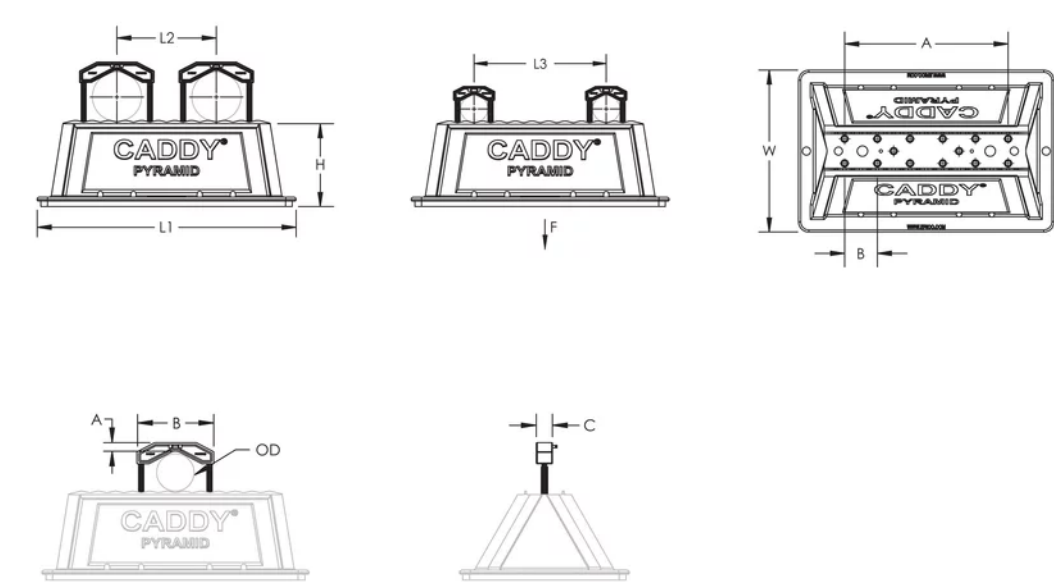

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

