

nVent CADDY Pyramid Universal Support



CARACTERISTICI

Captive stainless steel nuts allow for custom attachment methods to the support base including easy attachment of stainless steel strut, threaded rod or other project-specific hardware

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Multiple sizes and load ratings offer the ability to tailor the solution to the application

Includes square holes for creating an H-Frame with a 12" (305 mm) cross support (PBU16 only)

Base is manufactured from UV-stabilized thermoplastic material

SPECIFICAȚII

Static Load Safety Factor: 3:1

Temperature: -45 to 65 °C

Table 1/3

Număr de catalog	Article Number	Material	Length 1 (L1)	Length 2 (L2)	Height (H)	Width (W)
PBU6M	360495	Polyethylene, Polypropylene, Stainless Steel 18-8 (EN 1.4305)	140 mm	196 mm	102 mm	150 mm

Număr de catalog	Article Number	Material	Length 1 (L1)	Length 2 (L2)	Height (H)	Width (W)
PBU10M	360496	Polyethylene, Polypropylene, Stainless Steel 18-8 (EN 1.4305)	254 mm	318 mm	102 mm	201 mm
PBU16M	360497	Polyethylene, Polypropylene, Stainless Steel 18-8 (EN 1.4305)	406 mm	480 mm	102 mm	201 mm


Table 2/3

Număr de catalog	Article Number	Thread Size (TS)	Hole Quantity	A	B	Surface Area
PBU6M	360495	M10	3	114 mm	57 mm	26452mm ²
PBU10M	360496	M10	2	218 mm		59355mm ²
PBU16M	360497	M10	2	165 mm		91613mm ²

Table 3/3

Număr de catalog	Article Number	Static Load
PBU6M	360495	1330N
PBU10M	360496	4450N
PBU16M	360497	6670N

DIAGRAMS

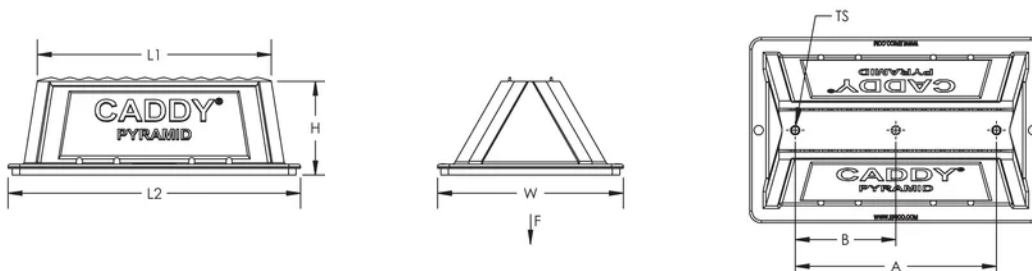

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

